

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0039271263
Status: Obsolete
Description: 2.54mm (.100") Pitch QF-50™, Vertical with Eject Levers, 26 Circuits

Documents:
[Drawing \(PDF\)](#)

General	
Product Family	Ribbon Cable / Wire Trap Connectors
Series	5576
Component Type	PCB Header
Glow-Wire Compliant	No
Product Name	QF-50™

Physical	
Circuits (Loaded)	26
Color - Resin	Black
Entry Angle	Vertical
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Number of Rows	2
PCB Retention	None
PCB Thickness - Recommended	1.60mm (.063")
Packaging Type	Tray
Pitch - Mating Interface	2.54mm (.100")
Plating min - Mating	0.102µm (4µ")
Plating min - Termination	3.048µm (120µ")
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Yes
Stackable	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40°C to +105°C
Termination Interface: Style	Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	N/A
Wire/Cable Type	Ribbon Cable

Electrical	
Current - Maximum per Contact	1A
Voltage - Maximum	250V

Material Info	
Old Part Number	5576-26BGS1

Reference - Drawing Numbers	
Product Specification	PS-5320-004
Sales Drawing	SD-5576-NB*

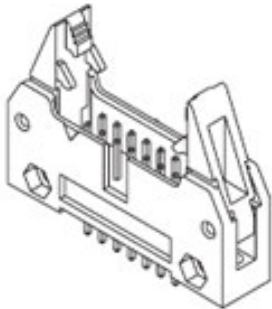


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
5576Series

Mates With
5320-NA|5320-NB

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION