

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19016-0037

Status:


Active

Overview:

Quick-Disconnect Terminals

Description:

Krimptite™ Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire, Box, Tab 2.79 x 0.81mm

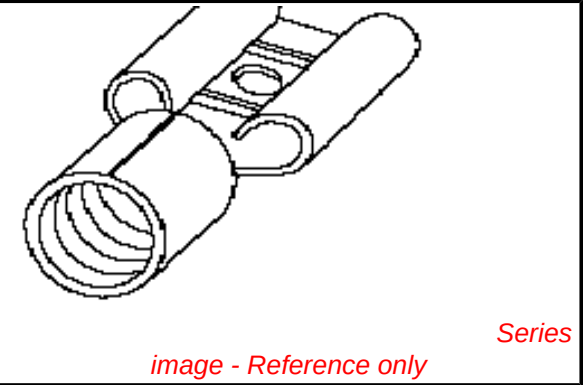

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-19902-005 \(PDF\)](#)

[Product Specification PS-19902-011 \(PDF\)](#)

[Product Specification PS-19902-013 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR18689
UL	E79133
General	
Product Family	Quick Disconnects
Series	19016
Comments	Butted Seam
Crimp Quality Equipment	Yes
Insulated	No
MolexKits	Yes
Overview	Quick-Disconnect Terminals
Product Name	Krimptite™
Type	Quick Disconnect
UPC	800755047202
Physical	
Barrel Type	Closed
Gender	Female
Glow-Wire Compliant	No
Insulation	None
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.308/g
Orientation	Straight
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Polarized to Mating Part	No
Tab Thickness	0.81mm
Tab Width	2.79mm
Temperature Range - Operating	Per Wire Specification
Termination Interface: Style	Crimp or Compression
Wire Size AWG	14, 16
Wire Size mm²	1.30 - 2.00
Electrical	
Voltage - Maximum	Per Wire Specification
Material Info	
Old Part Number	BB-1135
Reference - Drawing Numbers	
Product Specification	PS-19902-005, PS-19902-011, PS-19902-013

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series	
19016Series	
Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640071200
Hand Crimp Tool	0640031100
Hand Crimp Tool	0640031200
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640071100

This document was generated on 10/16/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION