

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19069-0192

Status:


Active

Overview:

Solderless Terminals

Description:

Krimptite™ Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 1/2" (M12), Length 32.51mm

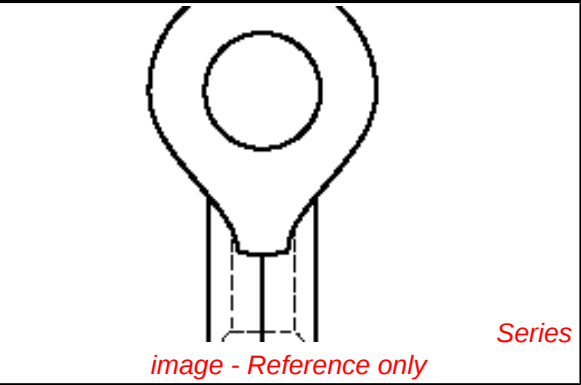

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19069
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Krimptite™
Type	Ring
UPC	800755067095

Physical	
Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	2.522/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	1/2" (M12)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	10, 12
Wire Size mm²	4.00 - 6.00

Material Info	
Old Part Number	C-101-12

Reference - Drawing Numbers	
Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	CCD10101

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19069Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640070100
PremiumGrade™ Hand Crimp Tool	0640030100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION