

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19054-0119](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp™ Ring Tongue Terminal for 14-16 Heavy Duty AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19054](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name InsulKrimp™
Type Ring
UPC 800753055070

Physical

Barrel Type Closed
Color - Resin Blue
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Net Weight 1.052/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size M10
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 6.40mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30 - 2.00

Material Info

Old Part Number B-239-10X

Reference - Drawing Numbers

Product Specification PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing BCD20101

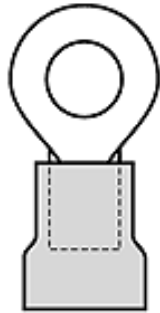


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19054Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade™	0640010100
Hand Crimp Tool	
Crimp Head for the	0640050100
AT-200™ Pneumatic	
Hand Tool	