

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [39357-0003](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 3.50mm Pitch Beau Eurostyle™ Fixed Mount PCB Terminal Block, 3 Circuits

Documents:
[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

Agency Certification
UL E48521


General
Product Family Terminal Blocks
Series [39357](#)
Application N/A
Component Type One Piece
Overview [Eurostyle™ Terminal Blocks](#)
Product Name Eurostyle™ Fixed Mount
Type Euro Block
UPC 756054634134

Physical
Circuits (Loaded) 3
Circuits (maximum) 3
Entry Angle Horizontal
Flammability 94V-0
Lock to Mating Part None
Number of Rows 1
Orientation Vertical
PC Tail Length 3.50mm
PCB Retention None
PCB Thickness - Recommended 1.60mm
Panel Mount No
Pitch - Mating Interface 3.50mm
Pitch - Termination Interface 3.50mm
Polarized to Mating Part No
Shrouded Fully
Stackable Yes
Surface Mount Compatible (SMC) No
Temperature Range - Operating -30°C to +85°C
Wire Size AWG 16, 18, 20, 22, 24, 26, 28
Wire Size mm² 0.20 - 1.00

Electrical
Current - Maximum per Contact 17.5A
Voltage - Maximum 300V

Material Info
Old Part Number 350103

Reference - Drawing Numbers
Sales Drawing SD-39357-001

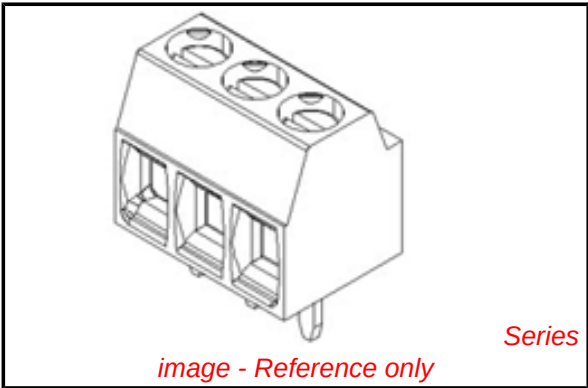

EU RoHS
RoHS Compliant by Exemption
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS

Pb

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[39357Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION