

UNIVERSAL ENCLOSURES

7000 Series Recessed Designer Cases


Functional yet modern design in nine different sizes with anti-scratch finish. Used by leading OEMs across numerous industries.

- Lid and base moulded in ABS
- Lid mounted by four M3 machine screws
- Plastic screw covers for aesthetic appearance
- Fine texture anti-scratch finish
- Recesses in lid and base designed to accept membrane keypads or overlays
- Integral mounting guides in lid and base for vertical PCB mounting
- PCB pillars in lid and base
- Surface mountable via moulded fixing points or wall-mounting kit (optional)
- Option of gasket included (For IP65)
- Option of RFI and gasket (For IP65 and RFI shielding)



Wall mounting kit

- Universal design fits all sizes, available in grey
- Fits lid and base, surface 1.5mm from lid or 9.5mm base

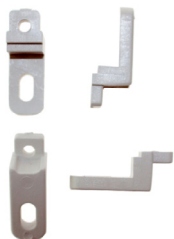

GREY	DESCRIPTION
CRDCWMKIT	4x mounting feet

SPECIFICATION

Materials	Lid, base & screw covers ABS, UL94-V0
Operating Temperature	Resistant to temperatures of up to 85°C
Protection class	IP54 as standard IP65 with gasket option
Standard colours	Grey
Standard unit includes	Base & lid 4x M3 Machine screws (Torque 0.5 Nm) 4x Screw covers
Options	Wall mounting kit IP65 gasket kits RFI Shielding

GREY	LENGTH	WIDTH	HEIGHT	DESCRIPTION
CRDCG0001	90mm	55mm	25mm	Designer Case
CRDCGG001	90mm	55mm	25mm	With Gasket
CRDCERG01	90mm	55mm	25mm	With RFI & Gasket
CRDCG0002	90mm	55mm	40mm	Designer Case
CRDCGG002	90mm	55mm	40mm	With Gasket
CRDCERG02	90mm	55mm	40mm	With RFI & Gasket
CRDCG0003	110mm	85mm	35mm	Designer Case
CRDCGG003	110mm	85mm	35mm	With Gasket
CRDCERG03	110mm	85mm	35mm	With RFI & Gasket
CRDCG0004	127mm	75mm	30mm	Designer Case
CRDCGG004	127mm	75mm	30mm	With Gasket
CRDCERG04	127mm	75mm	30mm	With RFI & Gasket
CRDCG0005	127mm	75mm	45mm	Designer Case
CRDCGG005	127mm	75mm	45mm	With Gasket
CRDCERG05	127mm	75mm	45mm	With RFI & Gasket
CRDCG0006	145mm	90mm	45mm	Designer Case
CRDCGG006	145mm	90mm	45mm	With Gasket
CRDCERG06	145mm	90mm	45mm	With RFI & Gasket
CRDCG0007	190mm	120mm	60mm	Designer Case
CRDCGG007	190mm	120mm	60mm	With Gasket
CRDCERG07	190mm	120mm	60mm	With RFI & Gasket
CRDCG0008	220mm	145mm	50mm	Designer Case
CRDCGG008	220mm	145mm	50mm	With Gasket
CRDCERG08	220mm	145mm	50mm	With RFI & Gasket
CRDCG0009	220mm	145mm	80mm	Designer Case
CRDCGG009	220mm	145mm	80mm	With Gasket
CRDCERG09	220mm	145mm	80mm	With RFI & Gasket

* This series is available in Black on request

7000-IP Gasket kits

- EPDM gasket, dust and water protection from IP54 to IP65

TYPE NO.	DESCRIPTION
CRDCGASK1	Gasket for Designer Case Size 1 and 2
CRDCGASK2	Gasket for Designer Case Size 3
CRDCGASK3	Gasket for Designer Case Size 4 and 5
CRDCGASK4	Gasket for Designer Case Size 6
CRDCGASK5	Gasket for Designer Case Size 7
CRDCGASK6	Gasket for Designer Case Size 8 and 9



UNIVERSAL ENCLOSURES

HAND HELD CASES

HEAVY DUTY ENCLOSURES

DIN RAIL BOXES

INTERFACE SUPPORTS

CONTROL STATIONS

DIECAST & METAL BOXES

DESKTOP & INSTRUMENT CASES

POTTING BOXES

19" ENCLOSURES

19" CABINETS

DEVELOPMENT BOARD ENCLOSURES

CUSTOM SIZED ENCLOSURES

CUSTOM SERVICES



+44 (0)1638 716101
info@camdenboss.com
www.camdenboss.com

We operate a constant improvement policy, our products are subject to change without notice.

Ver 1.0 Iss 7

CAMDENBOSS
ELECTRONICS & ENCLOSURES