

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19069-0117](#)
Status: **Active**
Overview: Solderless Terminals
Description: Krimptite™ Ring Tongue Terminal for 14-16 AWG Wire

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19069
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Krimptite™
Type	Ring
UPC	800753068018

Physical


Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.611/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	10 (M5)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	14, 16
Wire Size mm²	1.30 - 2.00

Material Info

Old Part Number	BB-137-10T
-----------------	------------

Reference - Drawing Numbers

Product Specification	PS-19902-011
Sales Drawing	SD-19069-013

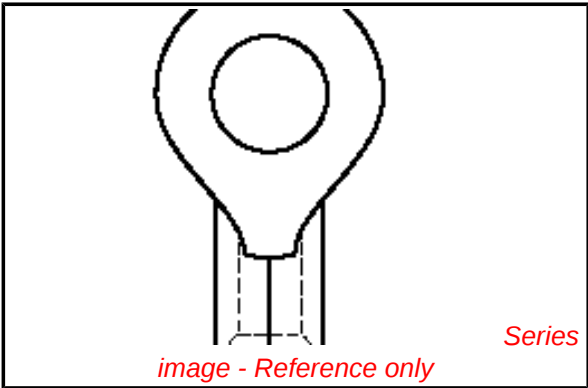

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19069Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Mini-Mac™	0638853900
Applicator, Air Feed	
Mylar Tape	
ATP Perishable	0190270068
Tool Kit used in ATP	
Presses that Process	
Product on Tape	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION