

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19069-0209](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite™ Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5), Length 19.94mm

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19069](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
MolexKits Yes
Overview [Solderless Terminals](#)
Product Name Krimptite™
Type Ring
UPC 800755067231

Physical

Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 1.488/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 10 (M5)
Termination Interface: Style Crimp or Compression
Wire Size AWG 10, 12
Wire Size mm² 4.00 - 6.00

Material Info

Old Part Number C-128-10

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
Sales Drawing CCD10101

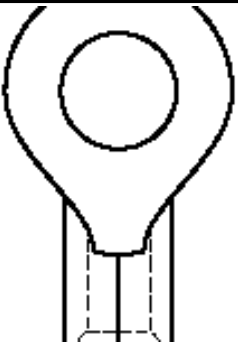


image - Reference only

Series

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19069Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640070100
PremiumGrade™ Hand Crimp Tool	0640030100