

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19002-0029](#)
Status: **Active**
Overview: [Quick-Disconnect Terminals](#)
Description: Avikrimp™ Fully Insulated Quick Disconnect, Female, for 14-16 AWG Wire, Mylar Tape

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-014 \(PDF\)](#)
[Product Specification PS-19902-015 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E79133

General

Product Family Quick Disconnects
Series [19002](#)
Crimp Quality Equipment Yes
Insulated Fully
Overview [Quick-Disconnect Terminals](#)
Product Name Avikrimp™
Type Quick Disconnect
UPC 800753027404

Physical

Barrel Type Closed
Color - Resin Blue
Flammability 94V-2
Gender Female
Glow-Wire Compliant Yes
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.983/g
Orientation Straight
Packaging Type Adhesive Tape on Reel
Polarized to Mating Part No
Tab Thickness 0.51mm
Tab Width 4.75mm
Temperature Range - Operating -65°C to +105°C
Wire Insulation Diameter 3.94mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30 - 2.00

Electrical


Voltage - Maximum 300V

Material Info

Old Part Number BB-5269T

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-014, PS-19902-015
Sales Drawing SD-19002-004

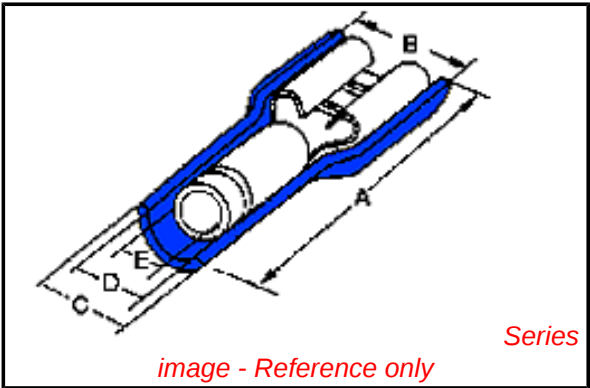

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19002Series](#)

Use With
[19001-0008](#) , [19001-0009](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Crimp Dies for MTA-100 Tape Applicator used in 3BF Press, MTA-105 Tape Applicator used in TM-2000™ Press, and ATP-301 Air Crimping Press for Mylar Tape Mounted Terminals	0192880130

This document was generated on 10/09/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION