

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

70107-0040

Status:


Active

Overview:

SL™ Modular Connectors

Description:

SL™ Wire-to-Wire Panel Mount Crimp Housing, Single Row, Version B, with Mounting Ears, 6 Circuits

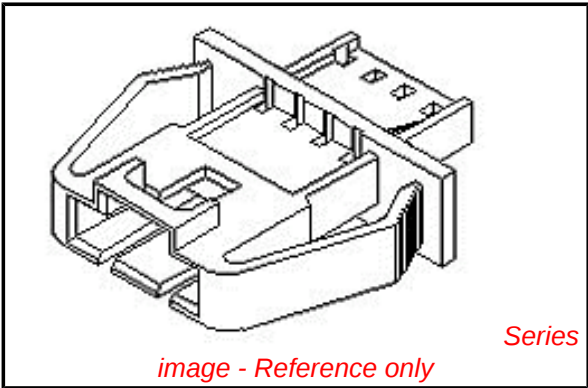

Documents:

3D Model

Drawing (PDF)

Product Specification PS-70400 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70107
Application	Signal, Wire-to-Wire
Overview	SL™ Modular Connectors
Product Name	SL™
UPC	800753560871
Physical	
Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-0
Gender	Male
Glow-Wire Compliant	No
Material - Resin	Polyester
Net Weight	1.617/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.54mm
Temperature Range - Operating	-40°C to +120°C
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-70400
Sales Drawing	SD-70107-0036-0059

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

70107Series

Mates With

70066 SL™ Crimp Housing A, G and D (Notes: Version C and H will not mate to the 70107 housing series), 70400 SL™ Insulation Displacement Connector Assembly, Version G Housing, 70430 SL™ Single Row Receptacle, Version G

Use With

70021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION