

DATA CENTRE CO-LOCATION CABINET

APPLICATION:

Hammond's Co-location Rack Cabinet features four (4) different bay configurations. Whether you are leasing the space or want to restrict access to sections of your cabinet, the Hammond CL Series is loaded with innovative features.

FEATURES:

- One single frame allows multiple bay configurations. Mounting space includes:
 - 1-Bay = 44U, 2-Bay = 21U, 3-Bay = 14U, 4-Bay = 10U
- Standard available configurations available in 36" and 42" depths.
- Vented shelves include rear removable panels for vertical PDU installations.
- Front and Rear Perforated Doors with 65% air flow.
- Doors include 4-pin combination lock with key override.
- Vertical Cable Managers can be installed either top or bottom. Designed to accommodate sliding rail mount kit on servers.
- Cabinet top includes removable top panel and provisions for containment system and cable trough accessories.

SPECIFICATIONS:


- 14-gauge welded steel frame; 16-gauge doors and side panel.
- Adjustable depth EIA-Compliant Adjustable depth mounting rails.
 - Available as Square Hole or Tapped (10-32) mounting rail.
- Recommended maximum weight load tested for 1,800 lbs.

FINISH:


- Rugged textured black powder paint

ADDITIONAL ACCESSORIES:


- Third set of rails can easily be added with either 10-32 taps or square holes.
- Security upgrade kit ensures entire cabinet is tamper-proof (see reverse).
- Bay upgrade kit divides a single bay into a 2, 3 or 4 bay cabinet (see reverse).
- Right-hand door hinge kit.

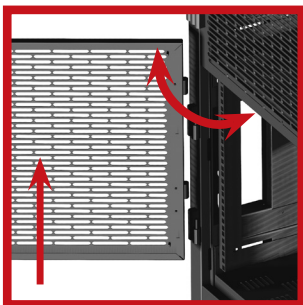

**To remove doors;
open and lift off.**

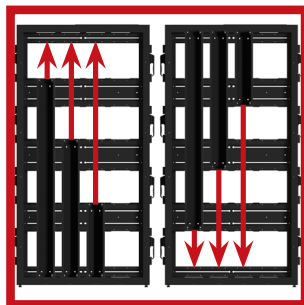

**Vertical Cable
Management can
easily be moved to
top or bottom.**

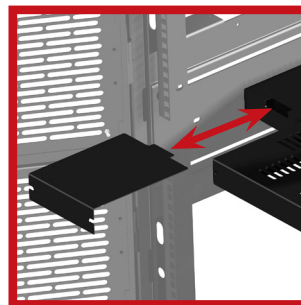

**Easily remove
cover panels
to install a
vertical PDU.†**



**One frame fits all
bay configurations.
Easily pass cables
between cabinets.**

DATA CENTRE CO-LOCATION CABINET

Use this chart to select your desired parts below. You may prefer to visit www.q-assembly.com and build your preferred solution online.

1 Bay (44U)

2 Bay (21U)

3 Bay (14U)

4 Bay (10U)

Step 1	Overall Dimensions 24" (W) x 83.4" (H)	Co-Location Frame is compatible with all bay configurations. In addition, the CL Frame can be used with the hot/cold aisle containment panels.	36" deep	☐ CLF244436BK	☐ CLF244436BK	☐ CLF244436BK	☐ CLF244436BK
			42" deep	☐ CLF244442BK	☐ CLF244442BK	☐ CLF244442BK	☐ CLF244442BK
Step 2 19" Mounting Rails		19" Tapped 10-32 Rails (Pair)		☐ CLTR44U	☐ CLTR21U	☐ CLTR14U	☐ CLTR10U
		19" Square Hole Rails (Pair)		☐ CLSR44U	☐ CLSR21U	☐ CLSR14U	☐ CLSR10U
Step 3 Side Panels		Solid Side Panels (Each)	36" deep	☐ CLSP4436BK (Compatible with all bay configurations)			
		Solid Side Panels (Each)	42" deep	☐ CLSP4442BK (Compatible with all bay configurations)			
Step 4 Internal Kit		Each kit contains the doors, cable managers and bay shelves.	36" deep	☐ CL1B36KIT	☐ CL2B36KIT	☐ CL3B36KIT	☐ CL4B36KIT
			42" deep	☐ CL1B42KIT	☐ CL2B42KIT	☐ CL3B42KIT	☐ CL4B42KIT
Step 5 Top Panel		Solid Top Panel		☐ C2T1923SBK1 (Compatible with all bay configurations)			
		Vented Top Panel		☐ C2T1923VBK1 (Compatible with all bay configurations)			
Step 6 Bottom Panel		Solid Bottom Panel	36" deep	☐ CLB2436 (Compatible with all bay configurations)			
		Solid Bottom Panel	42" deep	☐ CLB2442 (Compatible with all bay configurations)			
Step 7		Baying Kit		☐ GKIT (Compatible with all bay configurations)			
		Grounding Kit		☐ GRDKIT02 (Compatible with all bay configurations)			
		Seismic Bolt-Down Kit		☐ C4K-Z4 (Compatible with all bay configurations)			
		Security Upgrade Kit		☐ CLSECUPG (Compatible with all bay configurations)			
		Cable Trough		☐ CLTROUGH (Compatible with all bay configurations)			
		Right-hand door hinge kit.		☐ CLRHNG (Compatible with all bay configurations)			
		† PDU Semi-Toolless Mount Bracket		☐ PDU44U (Compatible with all bay configurations)			

Your **QUICK & EASY** configuration tool is just a **click** away!



Build your own assembly at: www.q-assembly.com