

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [90075-0035](#)  
**Status:** **Active**  
**Overview:** [Modular Plugs - Jacks](#)  
**Description:** [Modular Plug, Short Body, 6/4](#)

**Documents:**

[3D Model](#) [Application Specification AS-90075 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-90075 \(PDF\)](#)

**Agency Certification**

UL E107635

**General**


Product Family [Modular Jacks/Plugs](#)  
Series [90075](#)  
Component Type [Wire Plug](#)  
Magnetic [No](#)  
Overview [Modular Plugs - Jacks](#)  
Performance Category [3](#)  
Power over Ethernet (PoE) [N/A](#)  
Product Name [RJ11](#)  
UPC [800753746800](#)

**Physical**

Boot Color [N/A](#)  
Color - Resin [Clear](#)  
Durability (mating cycles max) [500](#)  
Flammability [94V-0](#)  
Inverted / Top Latch [N/A](#)  
Jack Height [N/A](#)  
Lightpipes/LEDs [None](#)  
Material - Metal [Phosphor Bronze](#)  
Material - Plating Mating [Gold](#)  
Material - Plating Termination [Tin](#)  
Material - Resin [Polycarbonate](#)  
Net Weight [0.915/g](#)  
Orientation [N/A](#)  
PCB Retention [None](#)  
Packaging Type [Bag](#)  
Pitch - Mating Interface [1.02mm](#)  
Pitch - Termination Interface [1.02mm](#)  
Plating min - Mating [1.270µm](#)  
Plating min - Termination [1.270µm](#)  
Ports [1](#)  
Positions / Loaded Contacts [6/4](#)  
Surface Mount Compatible (SMC) [No](#)  
Temperature Range - Operating [-40°C to +60°C](#)  
Termination Interface: Style [N/A](#)  
Waterproof / Dustproof [No](#)  
Wire/Cable Type [Flat Oval](#)

**Electrical**

Current - Maximum per Contact [1.5A](#)  
Grounding to Panel [N/A](#)  
Shielded [No](#)

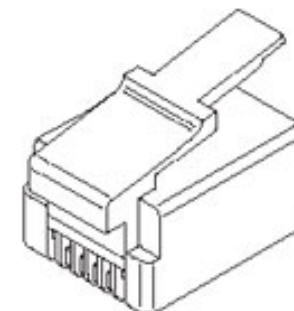

Series

image - Reference only

**EU RoHS**

**ELV and RoHS  
Compliant**

**REACH SVHC**

**Contains SVHC: No  
Low-Halogen Status  
Low-Halogen**

**China RoHS**



**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
For a multiple part number RoHS Certificate of  
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any  
non-product compliance questions.

**Search Parts in this Series**

[90075Series](#)

**Mates With**

[FCC 68 Jacks...](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are  
found by selecting the products below.  
Crimp Height Specifications are then  
contained in the Application Tooling  
Specification document.*

**Global**

Description	Product #
IDT - Manual Press	<a href="#">0011201273</a>
Parallel Action Handtool for Modular Plug, 6/4 Circuit, Short Body	<a href="#">0690081121</a>

Voltage - Maximum	125V DC
<b>Material Info</b>	
Old Part Number	A-90075-0035
<b>Reference - Drawing Numbers</b>	
Application Specification	AS-90075
Product Specification	PS-90075
Sales Drawing	SDA-90075

This document was generated on 10/06/2014

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**