

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [88768-5500](#)
Status: **Active**
Overview: [DMS-59®](#)
Description: 1.27mm Pitch DMS-59® (M)-to-Two DVI-D(M) Adapters Cable Assembly, 2.0m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-88768-55XX \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	88759
Assembly Configuration	Dual Ended Connectors
Connector to Connector	DMS-59™-to-DVI-D
Overview	DMS-59®
Product Name	DMS59®
UPC	756054583258
Physical	
Cable Length	2.0m
Circuits (Loaded)	59
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	Aluminum, Phosphor Bronze
Material - Plating Mating	Gold, N/A
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic, Polyester
Net Weight	286.000/g
Packaging Type	Bag
Pitch - Mating Interface	1.27mm
Plating min - Mating	0.254µm, 1.905µm
Plating min - Termination	2.540µm, 3.810µm
Single Ended	No
Termination Interface: Style	N/A, Solder or Weld, Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	30
Wire/Cable Type	Round
Electrical	
Current - Maximum per Contact	1A
Impedance	100#
Shielded	Yes
Voltage - Maximum	30V AC
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-88768-55XX
Sales Drawing	SD-88744-099, SD-88768-099

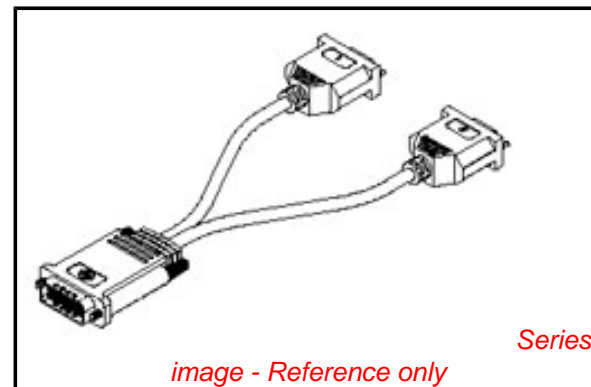


image - Reference only

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
 Not Reviewed
Low-Halogen Status
 Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[88759Series](#)