




EGG.2K.310.CYM

MECHANICAL DETAILS

Shell Style Model	EG* : Fixed receptacle nut fixing
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Housing Material	Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces
Cable Fixing	0 - 0 mm
Variant 2	:

			E	L	M	N	S1	S3
Mm.			9	30.7	5	28.6	18.5	24
In.			0.35	1.21	0.20	1.13	0.73	0.94

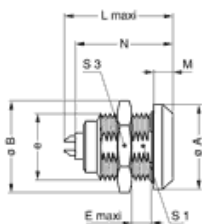

PERFORMANCE DETAIL

Insert	2K.310 : 10 Low Voltage
Insulator	Y: PEEK for crimp contacts
Specifications	
Contact Type:	Crimp
Max. Matings:	5000
Contact	30 N
Contact Dia.:	0.9 mm (0.035in)
Bucket Dia.:	1.1 mm (0.043in)
Min. Conductor:	0.25 mm ² (AWG 24)
Max. Conductor:	0.5 mm ² (AWG 20)
R (max):	4.8 mOhm
Positioner:	DCE.91.092.BVM

 


OTHER CHARACTERISTICS

Endurance (Shell)	Endurance (Shell):
Temp (min)	-55°C
Temp (max)	+200°C
Humidity (max):	<=95% [at 60 deg C /140 F]
Vibration:	15 g [10 Hz - 2000 Hz]
Shock Resistance:	100 g [6 ms]
Salt Spray	>144 hr
Climatical	50/175/21
Shielding (min):	95 dB (10 MHz)
Shielding (min):	80 dB (1 GHz)
IP Rating	68



Available Download



unipole_multipole.pdf

Related links



Contact



Quote Request



Catalogs Downloads



Catalogs Requests



Sample Request



3D drawings