

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19070-0155

Status:


Active

Overview:

Solderless Terminals

Description:

InsulKrimp™ Ring Tongue Terminal for 10-12 AWG Wire

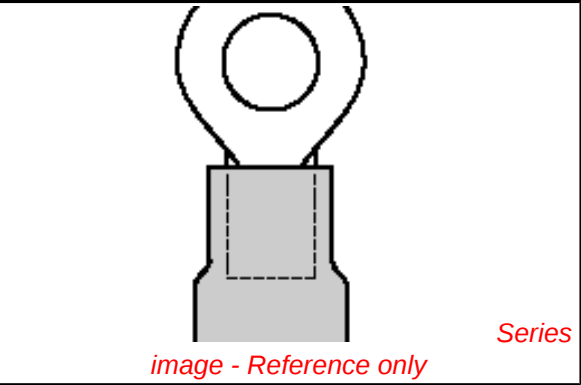

Documents:	
Drawing (PDF)	Product Specification PS-19902-013 (PDF)
Product Specification PS-19902-009 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011 (PDF)	

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19070
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	InsulKrimp™
Type	Ring
UPC	800753069954
Physical	
Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	2.558/g
Packaging Type	Bag
Stud Size	5/16" (M8)
Wire Insulation Diameter	6.40mm max.
Wire Size AWG	10, 12
Wire Size mm²	3.30 - 5.00
Material Info	
Old Part Number	C-240-56X
Reference - Drawing Numbers	
Product Specification	PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing	SD-19070-007

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19070Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300
Hand Crimp Tool	0640010300