

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19084-0004](#)
Status: **Active**
Overview: Solderless Terminals
Description: Open Barrel Star Ring , Tin-Plated Brass, for 14-18 AWG Wire Range, Stud Size 6 (M3.5)

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-006 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series [19084](#)
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview [Solderless Terminals](#)
 Product Name N/A
 Type Ring
 UPC 800755080193

Physical


Barrel Type Open
 Insulation None
 Material - Plating Mating Tin
 Net Weight 0.827/g
 Packaging Type Reel
 Plating min - Mating 2.540µm
 Plating min - Termination 2.540µm
 Stud Size 6 (M3.5)
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter N/A
 Wire Size AWG 14, 16, 18
 Wire Size mm² 0.80 - 2.00

Material Info

Old Part Number SRZ-4129-06

Reference - Drawing Numbers

Product Specification PS-19902-006, PS-19902-011
 Sales Drawing SD-19084-001

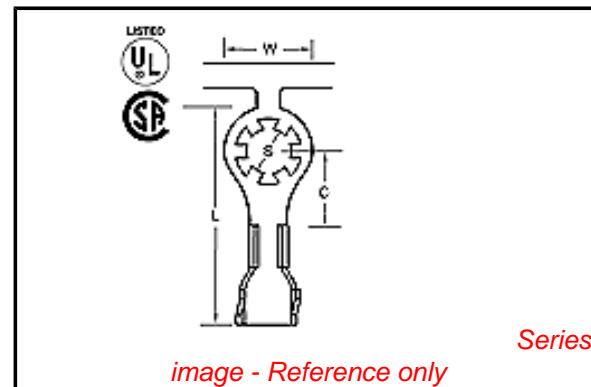

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[19084Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Mini-Mac™ Applicator	0638815600
ASP Perishable Tool Kit used in ASP presses that process metal strip product	0190290053