

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [09-50-7081](#)
Status: **Active**
Overview: [KK® Interconnect System - Molex](#)
Description: [KK® 3.96mm Crimp Terminal Housing, 8 Circuits](#)

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-08-50 \(PDF\)](#)
[Packaging Specification PK-2139-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Crimp Housings
Series [2139](#)
Application Power, Wire-to-Board
Overview [KK® Interconnect System - Molex](#)
Product Name KK® 396
UPC 800753531543

Physical

Circuits (maximum) 8
Color - Resin Natural
Flammability 94V-2
Gender Female
Glow-Wire Compliant No
Material - Resin Nylon
Net Weight 2.048/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.96mm
Temperature Range - Operating See Product Specification

Material Info

Old Part Number 2139-8C

Reference - Drawing Numbers

[Packaging Specification](#) PK-2139-001
[Product Specification](#) PS-08-50
[Sales Drawing](#) SD-2139

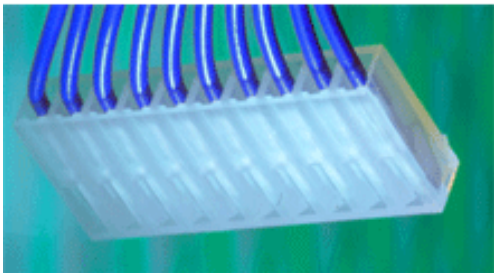


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[2139Series](#)

Use With
[2478](#) Crimp Terminals for 18-24 AWG, [2578](#) Crimp Terminals for 22-26 AWG