

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [43914-1102](#)
Status: **Active**
Overview: Mini-Fit Sr.™ Power Connectors
Description: 10.00mm Pitch Mini-Fit Sr.™ Receptacle Housing, Dual Row, 8 Circuits

Documents:

[3D Model](#) [Test Summary TS-42815-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-42815-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [43914](#)
 Application Power, Wire-to-Board, Wire-to-Wire
 Overview [Mini-Fit Sr.™ Power Connectors](#)
 Product Name Mini-Fit Sr.™
 UPC 800753933668

Physical

Circuits (maximum) 8
 Color - Resin Black
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Material - Resin Polyester
 Net Weight 13.280/g
 Number of Rows 2
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 10.00mm
 Stackable No
 Temperature Range - Operating -40°C to +105°C


Electrical

Current - Maximum per Contact 50A

Material Info

Reference - Drawing Numbers

Product Specification PS-42815-001, RPS-42815-001, RPS-42815-011,
 RPS-42815-012, RPS-42815-013, RPS-42815-014,
 RPS-42815-015
 Sales Drawing SD-43914-002
 Test Summary TS-42815-001

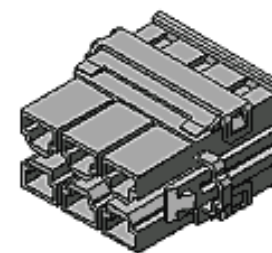

Series

image - Reference only

EU RoHS

**ELV and RoHS
 Compliant**
**REACH SVHC
 Contains SVHC: No**
**Low-Halogen Status
 Not Low-Halogen**

China RoHS



**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[43914Series](#)

Mates With

[43915](#) , [43938](#)

Use With

[42815](#) Female Terminal and [43980](#) TPA Clip