

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 50-57-9702
Status: Active
Overview: SL™ Modular Connectors
Description: SL™ Crimp Housing, Single Row, Version N, TPA™ with Positive Latch, 2 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-70400 \(PDF\)](#)
[Product Specification PS-71851 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series 70066
Application Signal, Wire-to-Board
Comments Version N
Overview SL™ Modular Connectors
Product Name SL™
UPC 800754788748

Physical

Circuits (maximum) 2
Color - Resin Black
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Keying to Mating Part Yes
Lock to Mating Part Yes
Material - Resin Polyester Alloy
Net Weight 0.215/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Electrical


Current - Maximum per Contact 3A

Material Info

Old Part Number 70066-0386

Reference - Drawing Numbers

Product Specification PS-70400, PS-71851
Sales Drawing SD-70066-386

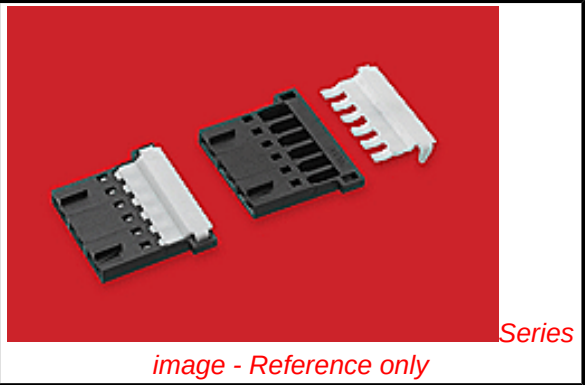

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
70066Series

Mates With
70018 , 70543 , 70545 , 70553 , 70555 ,
70107 , 70541 , 70551 , 70634

Use With
SL™ Crimp Terminal 70058 , 71851 , TPA
for SL TPA series housings 73838-0002