

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19073-0202

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp™ Ring Tongue Terminal for 10 to 12 AWG Wire, Stud Size 5/16" (M8), Expanded Flare, Length 31.95mm

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19073

Crimp Quality Equipment

Yes

Mil-Spec

N/A

Overview

Solderless Terminals

Product Name

Avikrimp™

Type

Ring

UPC

800753077409

Physical

Barrel Type

Closed

Flammability

94V-2

Insulation

Nylon (PA)

Material - Plating Mating

Tin

Net Weight

2.544/g

Packaging Type

Bag

Stud Size

5/16" (M8)

Wire Insulation Diameter

6.35mm max

Wire Size AWG

10, 12

Wire Size mm²

4.00 - 6.00

Material Info

Old Part Number

C-830-56X


Reference - Drawing Numbers

Product Specification

PS-19902-011

Sales Drawing

CCD80105

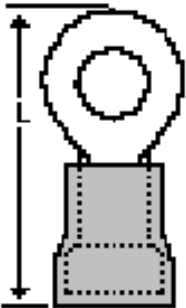

Series

image - Reference only

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19073Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION