

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [15-38-1026](#)
Status: **Active**
Overview: [C-Grid® Products](#)
Description: 2.54mm Pitch C-Grid® Shunt Terminal Housings, Overall Tin (Sn), 2 Circuits, with Pin Stop

Documents:

- [3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-7859 \(PDF\)](#)
- [Test Summary TS-7859-0001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Accessories
Series	7859
Component Type	Shunt
Overview	C-Grid® Products
Product Name	C-Grid®, C-Grid III™, SL™
UPC	800753604353

Physical

Circuits (Loaded)	2
Color - Resin	Black
Flammability	94V-0
Lock to Mating Part	No
Material - Metal	Phosphor Bronze
Material - Resin	Polyester
Net Weight	0.164/g
Number of Rows	1
Packaging Type	Bag
Temperature Range - Operating	-40°C to +105°C

Electrical


Current - Maximum per Contact	5A
-------------------------------	----

Material Info

Old Part Number	7859-2A164N
-----------------	-------------

Reference - Drawing Numbers

Product Specification	PS-7859
Sales Drawing	SDA-7859-2A***N
Test Summary	TS-7859-0001

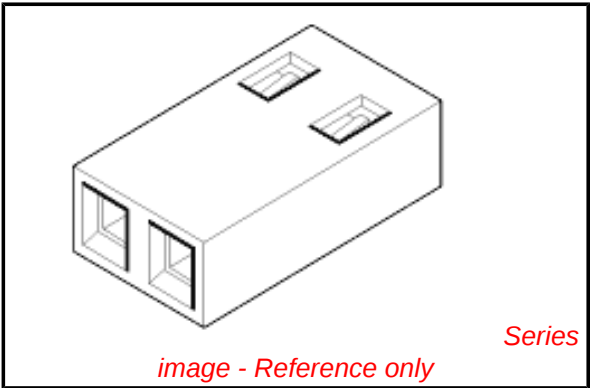

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[7859Series](#)

Use With
70280 C-Grid Breakaway Header, 71308 C-Grid® Header, [71764](#) C-Grid® Breakaway Header, [42375](#) KK® Breakaway Header, [42377](#) KK® Breakaway Header, 4030 KK® Wire-to-Board Header, [42152](#) KK® Wire-to-Board Header