

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19071-0250

Status:

Active

Overview:

Solderless Terminals

Description:

InsulKrimp™ Ring Tongue Terminal for 4 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19902-009 (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19071

Crimp Quality Equipment

Yes

Mil-Spec

N/A

Overview

Solderless Terminals

Product Name

InsulKrimp™

Type

Ring

UPC

800753072060

Physical

Barrel Type

Closed

Color - Resin

Natural

Flammability

94V-0

Insulation

PVC

Material - Plating Mating

Tin

Net Weight

10.075/g

Packaging Type

Bag

Stud Size

10 (M5)

Wire Insulation Diameter

13.10mm max.

Wire Size AWG

4

Material Info

Old Part Number

F-667-10X

Reference - Drawing Numbers

Product Specification

PS-19902-009, PS-19902-011, PS-19902-013

Sales Drawing

SD-19071-004

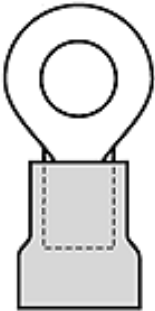


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19071Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Hydraulic Dieless Crimping Tool	0638161700
Hand Crimp Tool	0640013900
Hand Crimp Tool for 4 AWG Insulated Ring Terminals	0640017870
Die Set (large) for the HHLS Hydraulic Crimper	0192890007
Manual Putt Pump Hydraulic System, Die set required	0192860117

This document was generated on 12/10/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION