

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19099-0007](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: InsulKrimp™ Snap Spade Terminal for 18-22 AWG Wire, Red

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19099](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name InsulKrimp™
Type Spade Snap
UPC 800753088740

Physical


Barrel Type Closed
Color - Resin Red
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Net Weight 0.578/g
Packaging Type Bag
Stud Size 5 (M3)
Wire Insulation Diameter 4.40mm max.
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35 - 0.80

Material Info

Old Part Number AA-2704-05X

Reference - Drawing Numbers

Product Specification PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing AACD20502

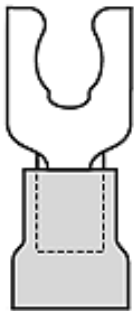

Series

image - Reference only

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19099Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300
Hand Crimp Tool	0640010300