

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19118-0086

Status:

Active

Overview:

Solderless Terminals

Description:

Krimptite™ Flanged Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 8 (M4), Length 19.56mm

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19118

Crimp Quality Equipment

Yes

Mil-Spec

N/A

Overview

Solderless Terminals

Product Name

Krimptite™

Type

Spade

UPC

800755082814

Physical

Barrel Type

Closed

Insulation

None

Material - Plating Mating

Tin

Net Weight

1.511/g

Packaging Type

Bag

Plating min - Mating

4.064µm

Plating min - Termination

4.064µm

Stud Size

8 (M4)

Wire Size AWG

10, 12

Wire Size mm²

4.00 - 6.00

Material Info

Old Part Number

C-117-08


Reference - Drawing Numbers

Product Specification

PS-19902-011, PS-19902-013

Sales Drawing

SD-19118-002

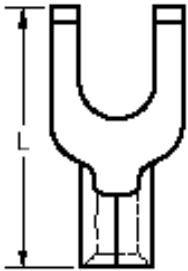

Series

image - Reference only

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19118Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade™ Hand Crimp Tool	0640030100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640070100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION