


# ADVANCED SERIES



- Design innovativo / linee morbide
- Impilabilità (solo art. 170/25 e 170/28)
- Materiale: polipropilene
- Innovative design with soft lines
- Stackable (only art. 170/25 & 170/28)
- Material: polypropylene

Dimensioni interne Internal dimensions	A	B	C	D	E	Colori disponibili Colours available	Colori serrature Clips colours
<b>Art. 170/25 Imp</b> <b>Art. 170/25T Imp</b>	235* (9.25)	185* (7.28)	30* (1.18)	13* (0.51)	163* (6.42)		
<b>Art. 170/26H44</b>	248* (9.76)	178* (7.01)	19.5* (0.77)	19.5* (0.77)	160* (6.30)		
<b>Art. 170/26H76</b>	247* (9.72)	177* (6.95)	35.5* (1.40)	35.5* (1.40)	159* (6.26)		
<b>Art. 170/28</b> <b>Art. 170/28T</b>	272* (10.71)	215* (8.47)	51* (2.01)	22* (0.87)	190* (7.48)		
<b>Art. 170/30N</b>	312* (12.28)	250* (9.84)	63* (2.48)	52* (2.04)	225* (8.86)		
<b>Art. 170/37</b>	363* (14.30)	256* (10.08)	83* (3.27)	32* (1.26)	244* (9.60)		
<b>Art. 170/37T</b>	363* (14.30)	256* (10.08)	83* (3.27)	32* (1.26)	244* (9.60)		
<b>Art. 170/38N</b>	385* (15.16)	260* (10.24)	55* (2.17)	43* (1.69)	235* (9.25)		
<b>Art. 170/51N</b>	510* (20.08)	370* (14.57)	64.5* (2.54)	64.5* (2.54)	335* (13.19)		

\*= mm.  
( )= inch.  
 =Transparent

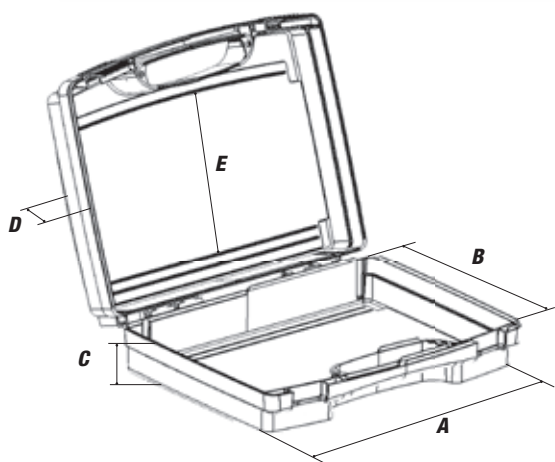

Spugne bugnate (GPB)  
Convolved foams (GPB)