

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


50217-9101

Status:

Active

Description:

3.50mm Pitch Crimp Terminal 50217, 18-24 AWG, Bag, Brass

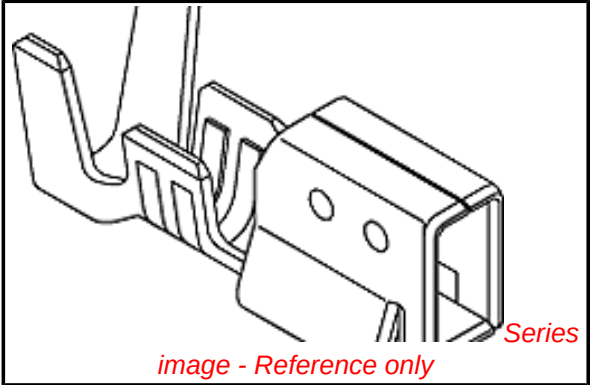

- Documents:
- 3D Model

Drawing (PDF)

Product Specification PS-51067-001 (PDF)

Product Specification PS-51067-002 (PDF)

Product Specification PS-51067-005 (PDF)

Product Specification PS-51067-007 (PDF)

Product Specification PS-51067-008 (PDF)

Product Specification PS-51067-016 (PDF)

Product Specification PS-51067-017 (PDF)

Product Specification PS-51067-019 (PDF)

Product Specification PS-51067-020 (PDF)

Product Specification PS-51067-021 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	50217
Application	Signal
Crimp Quality Equipment	Yes
Packaging Alternative	50217-9001 (Reel)
Product Name	N/A
UPC	800754369671
Physical	
Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	238.300/mg
Packaging Type	Bag
Plating min - Mating	0.889µm
Plating min - Termination	0.889µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.40-3.00mm
Wire Size AWG	18, 20, 22, 24
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Product Specification	PS-51067-001, PS-51067-002, PS-51067-005, PS-51067-007, PS-51067-008, PS-51067-016, PS-51067-017, PS-51067-019, PS-51067-020, PS-51067-021, RPS-35156-002, RPS-35156-003, RPS-35156-101, RPS-51067-002, RPS-51067-003, RPS-51067-015, RPS-51067-020, RPS-51067-021, RPS-51067-022, RPS-51067-023, RPS-51067-025, RPS-51067-028, RPS-51067-031, RPS-51067-032, RPS-51067-035, RPS-51067-037, RPS-51067-040, RPS-51067-041, RPS-51067-043
Sales Drawing	SD-50217-****

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

50217Series

Mates With

50419

Use With

51067

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
FineAdjust™	0638603000
Applicator, Large	
Insulation	
Hand Crimp Tool, UL	0638118300
Approved	

FineAdjust™ Applicator, Small Insulation Extraction Tool	<u>0638603100</u> <u>0638132700</u>
Japan Description	Product #
Hand Crimper - UL1007	<u>0571895000</u>
Hand Crimper - UL1015	<u>0571905000</u>

This document was generated on 12/16/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION