

Data Sheet
3-651-15 DR EUROline-Conductive



Part Number **3-651-15 DR**

Special pliers made from high grade special steel for extremely high requirements;
by precision inductive hardness process blades achieve up to 65 HRC

Box joint

precise jaw adjustment without backlash

fine polished and bright burnished surface

Double leaf spring from stainless steel

Ergonomically formed bicoloured hand guard from dissipative anti-slide material

The pliers of this programme have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas.



Description: Mini side cutters EUROline-Conductive with very slim, rounded head, for finest operations, with retaining spring

Characteristics:

Blade Finish Flush



Cutting capacity soft wire Ø 1.5 mm


Cutting capacity medium wire Ø 0.8 mm

cutting capacity hard wire -

A - Head width 10 mm

B - Head thickness 6.5 mm

C - Blade / jaw length 9.5 mm

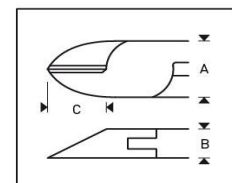

Length 120 mm

Weight 65 g

Customs Tariff No. 82032000

EAN-No. 4250838502641



Link to catalogue page www.bernstein-werkzeuge.de/Katalogseiten/EUROline-Conductive_English.pdf

Link to image <http://www.bernstein-werkzeuge.de/Artikelbilder/03/3-651-15 DR.jpg>

Image file 3-651-15 DR.jpg

Keywords pliers; electronic pliers; side cutters