

**Data Sheet**  
**3-653-15 EUROline-Conductive**



**Part Number** 3-653-15

Special pliers made from high grade special steel for extremely high requirements;  
by precision inductiv hardness process blades achieve up to 65 HRC  
Box joint

precise jaw adjustment without backlash  
fine polished and bright burnished surface  
Double leaf spring from stainless steel



Ergonomically formed bicoloured hand guard from dissipative anti-slide material  
The pliers of this programm have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas.

**Description:** Mini side cutters EUROline-Conductive with very slim, pointed head, for finest operations, with special flat cutting edge


**Characteristics:**

Blade Finish Flush



Cutting capacity soft wire Ø 1.5 mm  
Cutting capacity medium wire Ø 0.8 mm  
cutting capacity hard wire -

A - Head width 10 mm  
B - Head thickness 6.5 mm  
C - Blade / jaw length 10 mm

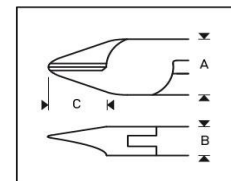

Length 120 mm

Weight 60 g

Customs Tariff No. 82032000



EAN-No. 4250838502665

Link to catalogue page [www.bernstein-werkzeuge.de/Katalogseiten/EUROline-Conductive\\_English.pdf](http://www.bernstein-werkzeuge.de/Katalogseiten/EUROline-Conductive_English.pdf)

Link to image <http://www.bernstein-werkzeuge.de/Artikelbilder/03/3-653-15.jpg>

Image file 3-653-15.jpg

Keywords pliers; electronic pliers; side cutters