

Part Number 3-688-15

Special pliers made from high grade special steel for extremely high requirements;
by precision inductiv hardness process blades achieve up to 65 HRC

Box joint

precise jaw adjustment without backlash

fine polished and bright burnished surface

Double leaf spring from stainless steel

Ergonomically formed bicoloured hand guard from dissipative anti-slide material


The pliers of this programm have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas.



Description: Flat nose pliers EUROline-Conductive
short ultra slim plain jaws

Characteristics:

Blade Finish	-
Cutting capacity soft wire	-
Cutting capacity medium wire	-
cutting capacity hard wire	-
A - Head width	8.5 mm
B - Head thickness	6.5 mm
C - Blade / jaw length	18 mm
Length	130 mm
Weight	60 g
Customs Tariff No.	82032000
EAN-No.	4250838502870

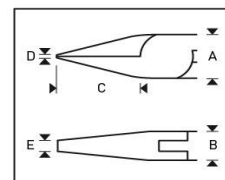

Link to catalogue page www.bernstein-werkzeuge.de/Katalogseiten/EUROline-Conductive_English.pdf

Link to image <http://www.bernstein-werkzeuge.de/Artikelbilder/03/3-688-15.jpg>

Image file 3-688-15.jpg

Keywords pliers; electronic pliers; flat nose pliers