

## Narrow-Tongue Copper Lug

### T&B Catalog Number:

**UPC Number:**

54162NT

**Status:**

78620986789

**Description:**

Active

Copper One-Hole Lug - Standard Barrel Narrow Tongue Lug - max 35KV, 3/0 AWG Wire, 1/4" Bolt Size, Tin Plated with Inspection Hole, Orange 50

#### General

Material	Copper
Finish	Tin Plated
Wire Size	3/0 AWG
Number of Studs	1
Stud Size	1/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Narrow
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Orange
Die Code	50

#### Dimension Information

A (inches)	1.680
B (inches)	0.650
C (inches)	0.632
D (inches)	0.125
E (inches)	0.632
F (inches)	0.250

#### Specifications

Voltage Rating	600V
----------------	------

#### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

#### Packaging

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	7 lbs. per 100

#### Application Support


T&B Sales Drawings	wsd-000288
T&B Instruction Sheets	ta00675-tb2

#### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

#### Certifications

RoHS Compliance	Yes
-----------------	-----

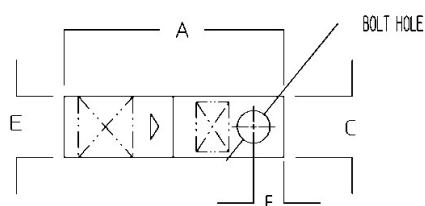

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)