

Sta-Kon®

Ferrule

T&B Catalog Number:

F2032

UPC Number:

78621035836

Status:

Active

Description:

Insulated Nylon Ferrule for Wire Size 16, Wire Size 1.5 mm², Length 0.65 inches, Black

WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

General

Ferrule Type	Insulated
Insulation Type	Insulated Nylon
Material	Copper
Finish	Electro -Tin Plated
Color	Black
Wire Range	16
Wire Size (mm ²)	1.50

Dimension Information

A (mm)	16.5
B (mm)	10.0
Diameter C (inches)	.071
Diameter C (mm)	1.8
Diameter D (inches)	.134
Diameter D (mm)	3.4
E (mm)	.15
A (inches)	.650
B (inches)	.394
E (inches)	.006

Specifications


Temperature Rating	105°C
Voltage Rating	300V
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	T1, T3, ERG2
Recommended Tool	T1, T3, ERG4

Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	5000
T&B Sold in UOM	Each
T&B Weight Per UOM	0.03 lbs. per 100

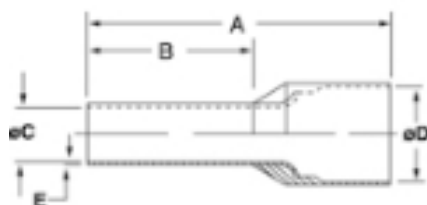

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Ferrule dimensions conform to DIN 46228, Part 4.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com