



Ferrule

T&B Catalog Number:

F2043

UPC Number:

78621033547

Status:

Active

Description:

Insulated Nylon Ferrule for Wire Size 8, Wire Size 10 mm², Length 0.827 inches, Red


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

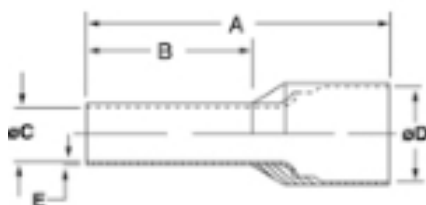

General

Ferrule Type	Insulated
Insulation Type	Insulated Nylon
Material	Copper
Finish	Electro -Tin Plated
Color	Red
Wire Range	8
Wire Size (mm ²)	10.00

Dimension Information

A (mm)	21.0
B (mm)	12.0
Diameter C (inches)	.181
Diameter C (mm)	4.6
Diameter D (inches)	.295
Diameter D (mm)	7.5
E (mm)	.20
A (inches)	.827
B (inches)	.472
E (inches)	.008

Specifications

Temperature Rating	105°C
Voltage Rating	300V
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	T3, ERG2
Recommended Tool	T3, ERG4

Packaging

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	1000
T&B Sold in UOM	Each
T&B Weight Per UOM	1.25 lbs. per 1000

Application Support

Overview	Available on Website
----------	----------------------

Wire Guide Tables

Available on Website

Notes

Ferrule dimensions conform to DIN 46228, Part 4.

Certifications

RoHS Compliance

Yes

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com