



Ferrule

T&B Catalog Number:

F8008

UPC Number:

78621033569

Status:

Active

Description:

Insulated Nylon Twin Ferrule for Wire Size 2x14, Wire Size 2x2.50 mm², Length 0.728 inches, Blue


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

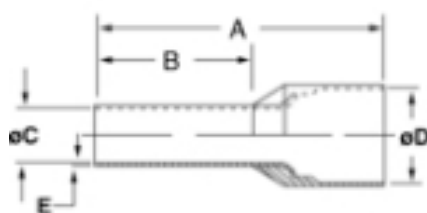

General

Ferrule Type	Insulated Twin
Insulation Type	Insulated Nylon
Material	Copper
Finish	Electro -Tin Plated
Color	Blue
Wire Range	2x14
Wire Size (mm ²)	2x2.50

Dimension Information

A (mm)	18.5
B (mm)	10.0
Diameter C (inches)	.114
Diameter C (mm)	2.9
Diameter D (inches)	.295
Diameter D (mm)	7.5
E (mm)	.15
A (inches)	.728
B (inches)	.394
E (inches)	.006

Specifications

Temperature Rating	105°C
Voltage Rating	300V
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	T3
Recommended Tool	T3

Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	5000
T&B Sold in UOM	Each
T&B Weight Per UOM	0.63 lbs. per 1000

Application Support

Overview	Available on Website
----------	----------------------

Wire Guide Tables

Available on Website

Notes

Ferrule dimensions conform to DIN 46228, Part 4.

Certifications

RoHS Compliance

Yes

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com