



Metal Clad Cable Termination Fittings & Accessories
T&B Catalog Number:

UPC Number: STE050
 78621082257
Status: Active
Description:

Star Teck Extreme aluminum jacketed cable fittings, hub size-1/2 in.

Features

- Powergrip grounding ring.
- Removable armor-stop for greater cable ranges.
- Elastomeric collar ring/busing for greater cable ranges.
- Built-in jacket stripping gauge on gland nut.
- Gland nut can be tightened with hammer and screwdriver.

Application

- Provides means for passing armored, metal clad, jacketed cable through a bulkhead or enclosure in hazardous areas. (these fittings are suitable for hazardous areas when used with T&B sealing compound).
- Form a mechanical grip and water and/or oil-resistant termination.
- Provide grounding continuity of cable armor.

General

Material: Aluminum
Strip Length (inches): 1 1/4

Dimension Information


Hub Size (inches): 1/2
Dimension B (inches): 2.650
Dimension C (inches): 1.630
A1: Throat Diameter Minimum (w/Armor Stop): 0.505
A2: Throat Diameter Minimum (wo/Armor Stop): 0.612
Range Over Jacket -Minimum (inches): 0.600
Range Over Jacket -Maximum (inches): 0.985
Range Over Armor -Minimum (inches): 0.520
Range Over Armor -Maximum (inches): 0.895
Strip Length (inches): 1 1/4

Packaging

Package in Units: 20
T&B Sold in UOM: Each
T&B Weight Per UOM: 20.69 lbs. per 100

Application Support

Product Specifications & Overview: Available on Website
 Available on Website

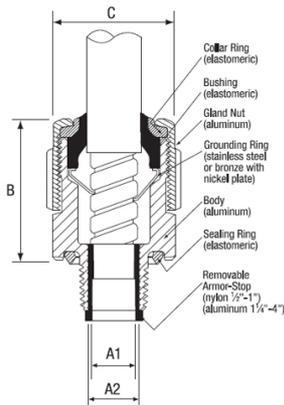

Product Brochure-Star Teck Extreme
Director™ Cable Fittings

Notes

*Note	UL Listed watertight NEMA Type 6P
**Note	1/2" Fittings do not have a removable armor stop.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E 38947

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com