


THR.209.S8L

TeeBox 7mm to 14mm cable max IP68 rated Screw fixing 4 cable entries 8 poles, retail pack

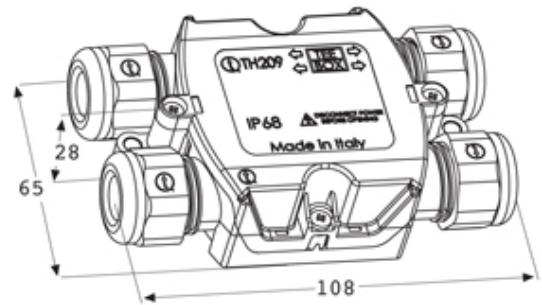

SPECIFICATION

Cable Entries	4
Number of Poles	8
Body Material	PA66 / SEBS/ TPE
Max Current (A)	16
Minimum Temp Rating °C	-40
IP Rating	68
Max Temp Rating °C	125
Minimum Cable Diameter (mm)	7
Maximum Cable Diameter (mm)	14
Fixing System	Screw
Temperature "T" Rating	T85

DISTRIBUTORS

