


### THR.390.S3T

TeeTube 3 Pole Screw - end barrier contact 7mm to 13.5mm, 4 mm max conductor size IP68 32A 450V 3 cable entries, retail pack

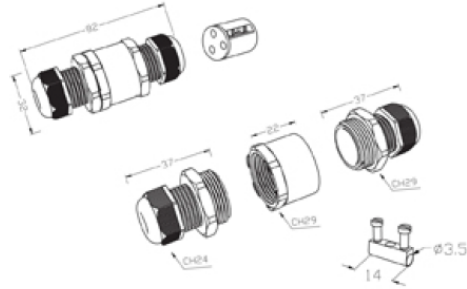

#### SPECIFICATION

Cable Entries	3
Number of Poles	3
Terminal Type	Screw - end barrier contact
Body Material	PA66 / TPE
Max Conductor Size (Sq mm)	4
Max Current (A)	32
Max Voltage (V)	450
Minimum Temp Rating °C	-40
IP Rating	68
Max Temp Rating °C	125
Minimum Cable Diameter (mm)	7
Maximum Cable Diameter (mm)	13.5
Fixing System	Cable
Temperature "T" Rating	T85

#### DISTRIBUTORS

