


Part Number: 336

Type	Size	Rating	Description
Incandescent	T6	14V 80mA	T-1 <sup>3</sup> / <sub>4</sub> Midget Groove Lamp

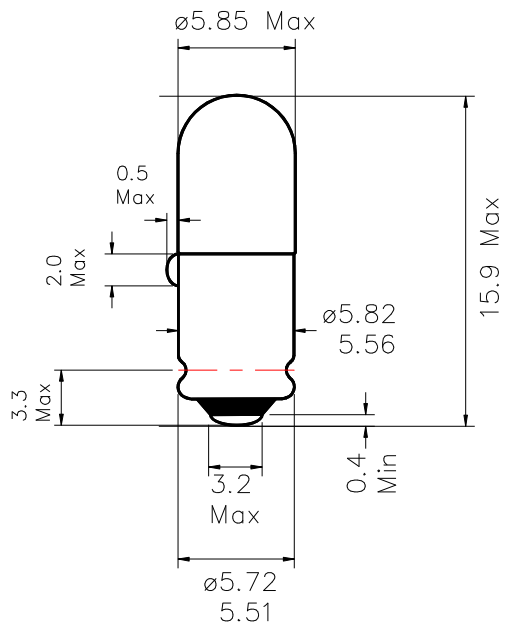

Dimensions in millimetres

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
14	72	80	88	4.7	6.3	7.9	1,500

Notes:

- 1 **Base Type** Nickel plated S5.7s
- 2 **Filament Shape** C-2F
- 3 **Lamp Marking** CML 336 14V 80mA
- 4 **Environmental** RoHS & REACH SVHC compliant