


PRODUCT DATA SHEET

Part Number: W503

| Type | Size | Rating | Description |
|--------------|------|------------|----------------------------------|
| Incandescent | T10 | 6.5V 300mA | T-3¼ Miniature Edison Screw Lamp |

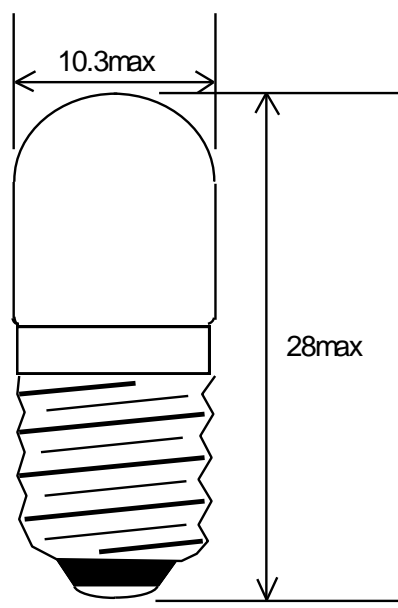

Dimensions in millimetres

| TEST VOLTS | CURRENT (mA) | | | LIGHT OUTPUT (Lm) | | | LIFE Hours |
|------------|--------------|------|------|-------------------|------|------|------------|
| | Min. | Nom. | Max. | Min. | Nom. | Max. | |
| 6.5 | 270 | 300 | 330 | 10 | 12 | 14 | 4000 |

Notes:

- 1 **Base Type** E10/13 (BS EN 60061-1)
- 2 **Filament Shape** C-2R
- 3 **LCL** 16mm nominal
- 4 **Bead colour** White or clear
- 5 **Lamp Marking** CML 6.5V 300mA
- 6 **Environmental** RoHS & REACH SVHC compliant