


Part Number : **505**

Type	Size	Rating	Description
Incandescent	T10	24V 3W	T-3¼ Wedgebase lamp

Dimensions(mm):

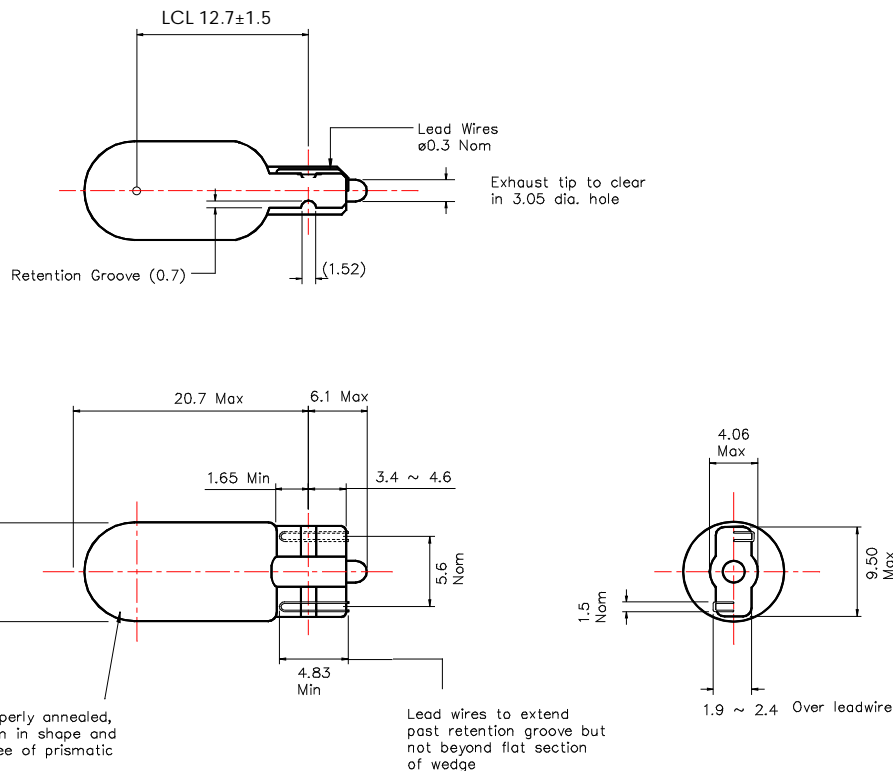

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28	122	143	164	15.4	22.0	28.6	1000

Notes:

- W2.1x9.5d in accordance with IEC 61-1, (BS EN 60061-1), sheet 7004-91-x.
- C-2F filament shape.
- Lamp marking (two line) **VCH 22A 24V W3W** (E11) where XY is a manufacturing date code
- Bead colour: White or clear
- RoHS and REACH SVHC compliant

Issue # 4 : 21 Mar 12