

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51021-0600](#)
Status: **Active**
Overview: [PicoBlade™ Connector System](#)
Description: 1.25mm Pitch PicoBlade™ Wire-to-Wire and Wire-to-Board Housing, Female, 6 Circuits

Documents:

| | |
|--|---|
| 3D Model | Product Specification PS-51021-023 (PDF) |
| Drawing (PDF) | Product Specification PS-51021-024 (PDF) |
| Product Specification PS-51021-001 (PDF) | Product Specification PS-51021-025 (PDF) |
| Product Specification PS-51021-002 (PDF) | Product Specification PS-51021-026 (PDF) |
| Product Specification PS-51021-009 (PDF) | Product Specification PS-51021-027 (PDF) |
| Product Specification PS-51021-010 (PDF) | Product Specification PS-51021-028 (PDF) |
| Product Specification PS-51021-011 (PDF) | Packaging Specification SPK-51021-001 (PDF) |
| Product Specification PS-51021-022 (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General

| | |
|----------------|---|
| Product Family | Crimp Housings |
| Series | 51021 |
| Application | Signal, Wire-to-Board, Wire-to-Wire |
| MolexKits | Yes |
| Overview | PicoBlade™ Connector System |
| Product Name | PicoBlade™ |
| UPC | 800753750456 |

Physical

| | |
|-------------------------------|----------------|
| Circuits (maximum) | 6 |
| Color - Resin | Natural |
| Flammability | 94V-0 |
| Gender | Female |
| Glow-Wire Compliant | No |
| Lock to Mating Part | Yes |
| Material - Resin | Polyester |
| Net Weight | 58.250/mg |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Panel Mount | No |
| Pitch - Mating Interface | 1.25mm |
| Polarized to Mating Part | Yes |
| Stackable | No |
| Temperature Range - Operating | -40°C to +85°C |


Electrical

| | |
|-------------------------------|----------|
| Current - Maximum per Contact | 0.8A, 1A |
|-------------------------------|----------|

Material Info

Reference - Drawing Numbers

| | |
|-------------------------|---|
| Packaging Specification | SPK-51021-001 |
| Product Specification | PS-51021-001, PS-51021-002, PS-51021-009, PS-51021-010, PS-51021-011, PS-51021-022, PS-51021-023, PS-51021-024, PS-51021-025, PS-51021-026, PS-51021-027, PS-51021-028, |

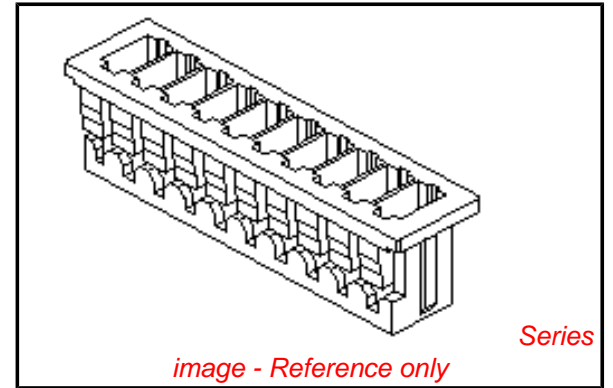

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[51021Series](#)

Mates With

[53261](#) 1.25mm Pitch PicoBlade™ Right Angle SMT Header, [53047](#) 1.25mm Pitch PicoBlade™ Vertical Thru-Hole Header, [53398](#) 1.25mm Pitch PicoBlade™ Vertical SMT Header, [53048](#) 1.25mm Pitch PicoBlade™ Right Angle Thru-Hole Header

Use With

[50058](#) Crimp Terminal, [50079](#) Crimp Terminal

RPS-51021-001, RPS-51021-002, RPS-51021-003,
RPS-51021-004, RPS-51021-006, RPS-51021-007,
RPS-51021-008, RPS-51021-009, RPS-51021-010,
RPS-51021-011, RPS-51021-013, RPS-51021-014,
RPS-51021-018, RPS-51021-019, RPS-51021-020,
RPS-51021-021, RPS-51021-023, RPS-51021-024,
RPS-51021-025, RPS-51021-028, RPS-51021-030,
RPS-51021-031, RPS-51021-032, RPS-51021-033,
RPS-51021-034, RPS-51021-037, RPS-51021-038,
RPS-51021-039, RPS-51021-040, RPS-51021-041,
RPS-51021-042, RPS-51021-043, RPS-51021-044,
RPS-51021-045, RPS-51021-046, RPS-51021-047,
RPS-51021-048, RPS-51021-051, RPS-51021-052,
RPS-51021-053, RPS-51021-054, RPS-51021-055,
RPS-51021-056, RPS-51021-057, RPS-51021-058,
RPS-51021-059, RPS-51021-060, RPS-51021-061,
RPS-51021-062, RPS-51021-063, RPS-51021-064,
RPS-51021-065, RPS-51021-066, RPS-51021-067,
RPS-51021-068, RPS-51021-071, RPS-51021-072,
RPS-51021-073, RPS-51021-074, RPS-51021-076,
RPS-51021-077, RPS-51021-078, RPS-51021-079,
RPS-51021-080, RPS-51021-081, RPS-51021-084,
RPS-51021-085, RPS-51021-086, RPS-51021-089,
RPS-51021-091, RPS-51021-092, RPS-51021-096,
RPS-51021-097, RPS-51021-101, RPS-51021-102,
RPS-51021-103, RPS-51021-104, RPS-51021-105,
RPS-51021-107, RPS-51021-108, RPS-51021-112,
RPS-51021-114, RPS-51021-115, RPS-51021-117,
RPS-51021-121, RPS-51021-122, RPS-53398-002,
RPS-53398-037, RPS-53398-038
SD-51021-002, SD-51021-005

Sales Drawing

This document was generated on 01/09/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION