

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

51353-3000

Status:

Active

Overview:

MicroClasp™ Wire-to-Board System

Description:

2.00mm Pitch MicroClasp™ Wire-to-Board Receptacle Housing, Positive Lock, Dual Row, 30 circuits

Documents:

3D Model

Drawing (PDF)

Product Specification PS-51353-003 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E29179

General

Product Family

Series

Application

Overview

Product Name

UPC

Crimp Housings

51353

Signal, Wire-to-Board

MicroClasp™ Wire-to-Board System

MicroClasp™

756054235850

Physical

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Compliant

Lock to Mating Part

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Stackable

Temperature Range - Operating

30

White

94V-0

Female

No

Yes

Nylon

1339.000/mg

2

Bag

No

2.00mm

No

-25°C to +85°C

Material Info

Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-51353-003, RPS-501844-001, RPS-51353-008, RPS-51353-009, RPS-51353-010, RPS-51353-013, RPS-51353-014, RPS-51353-016, RPS-51353-017, RPS-51353-018, RPS-51353-019, RPS-51353-020, RPS-51353-022, RPS-51353-024, RPS-51353-025, RPS-51353-026, RPS-51353-030, RPS-51353-034 SD-51353-002

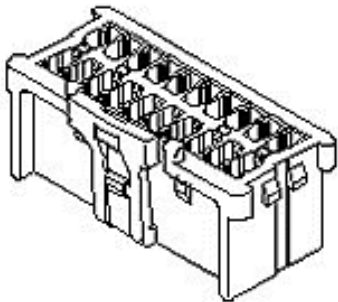


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

51353Series

Mates With

55917 Vertical Header with Kinked PC Tails, 55959 Right Angle Header, 501844 Vertical Header

Use With

56134 Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION