

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

55917-1830

Status:

Active

Overview:

MicroClasp™ Wire-to-Board System

Description:

2.00mm Pitch MicroClasp™ Wire-to-Board Header, Dual Row, Vertical, 18 Circuits, without PCB Locator

Documents:

3D Model

Drawing (PDF)

Product Specification PS-51353-003 (PDF)

Product Specification PS-51353-010 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E29179

General

Product Family

Series

Application

Overview

Product Name

UPC

PCB Headers

55917

Signal, Wire-to-Board

MicroClasp™ Wire-to-Board System

MicroClasp™

756054338957

Physical

Breakaway

Circuits (Loaded)

Circuits (maximum)

Color - Resin

Durability (mating cycles max)

First Mate / Last Break

Flammability

Glow-Wire Compliant

Guide to Mating Part

Keying to Mating Part

Lock to Mating Part

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Number of Rows

Orientation

PC Tail Length

PCB Locator

PCB Retention

PCB Thickness - Recommended

Packaging Type

Pitch - Mating Interface

Shrouded

Stackable

Surface Mount Compatible (SMC)

Temperature Range - Operating

Termination Interface: Style

No

18

18

Natural

30

No

94V-0

No

No

None

Yes

Tin

Tin

Polyester

1398.100/mg

2

Vertical

3.20mm

No

Yes

1.60mm

Tray

2.00mm

Fully

No

No

-25°C to +85°C

Through Hole

Electrical

Current - Maximum per Contact

Voltage - Maximum

3A

250V

Material Info

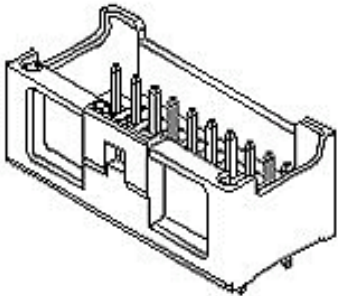


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

55917Series

Mates With

51353 MicroClasp™ Wire-to-Board Receptacle Housing

Reference - Drawing Numbers

Product Specification

PS-51353-003, PS-51353-010, RPS-501844-001,
RPS-51353-005, RPS-51353-008, RPS-51353-009,
RPS-51353-014, RPS-51353-016, RPS-51353-018,
RPS-51353-019, RPS-51353-020, RPS-51353-021,
RPS-51353-023, RPS-51353-024, RPS-51353-025,
RPS-51353-026, RPS-51353-028, RPS-51353-030
SD-55917-005

Sales Drawing

This document was generated on 01/15/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION