


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 19069-0112
Status: Active
Overview: Solderless Terminals
Description: Krimptite™ Ring Tongue Terminal for 14-16 AWG Wire

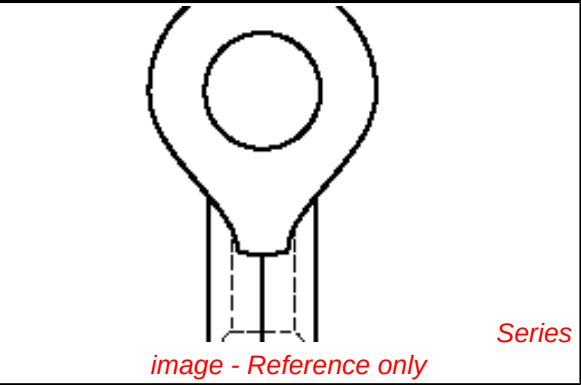

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series 19069
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Krimptite™
Type Ring
UPC 800755066883

Physical

Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.678/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 5-6 (M3-3.5)
Termination Interface: Style Crimp or Compression
Wire Size AWG 14, 16
Wire Size mm² 1.30 - 2.00

Material Info

Old Part Number BB-137-06

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
Sales Drawing SD-19069-013

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

19069Series

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
PremiumGrade™ Hand Crimp Tool	0640030100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640070100