

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19070-0121

Status:


Active

Overview:

Solderless Terminals

Description:

InsulKrimp™ Ring Tongue Terminal for 10-12 AWG Wire

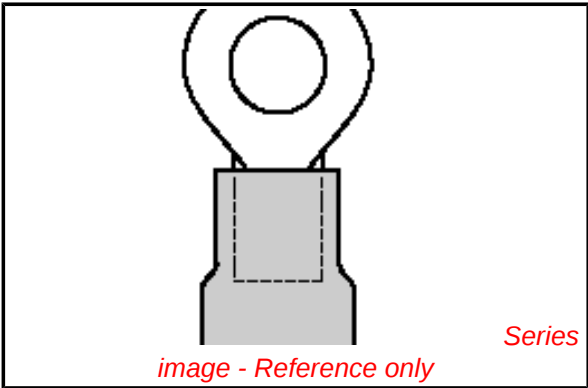

Documents:

Drawing (PDF)

Product Specification PS-19902-009 (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19070
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	InsulKrimp™
Type	Ring
UPC	800753069688

Physical	
Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	1.909/g
Packaging Type	Bag
Stud Size	8 (M4)
Wire Insulation Diameter	6.40mm max.
Wire Size AWG	10, 12
Wire Size mm²	3.30 - 5.00

Material Info	
Old Part Number	C-228-08X

Reference - Drawing Numbers	
Product Specification	PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing	SD-19070-007

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19070Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300
Hand Crimp Tool	0640010300

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION