

Neon & LED Indicator Lights Sealed to IP52 and IP54

Colours and voltages:

Neon Red, Amber, Green
120 or 230Vac 0.5W - please specify (Red base)

LED Red, Amber, Green
28Vac/dc 1W (Green base)

Neon versions feature integral current limiting & ghost lighting resistors.
LED versions have rectifier diodes & resistors for direct connection to 28Vac/dc.

To order

Select a number from the "type" column, then state:
Lens colour, voltage and whether neon or LED. All versions have recessed screw terminals. IP52 is standard. A panel sealing washer is available for IP54.

- ▶ IP52 and IP54 sealing
- ▶ Three bezel sizes: 18.0, 20.5 and 30.0 diameter
- ▶ Neon or LED indicator
- ▶ Black and satin chrome bezel or without bezel
- ▶ Recessed screw terminals






Approvals and specifications



Approval shown for neon versions only


TERM	TYPE	PANEL & °C
Recessed Screw 	3130 No bezel 	 T120 neon T50 LED
Recessed Screw 	3160 Black bezel 	 T120 neon T50 LED
Recessed Screw 	3161 Satin chrome style bezel 	 T55 neon T50 LED
Recessed Screw 	3221 Large black bezel 	 T120 neon T50 LED

DIMENSIONS (mm)

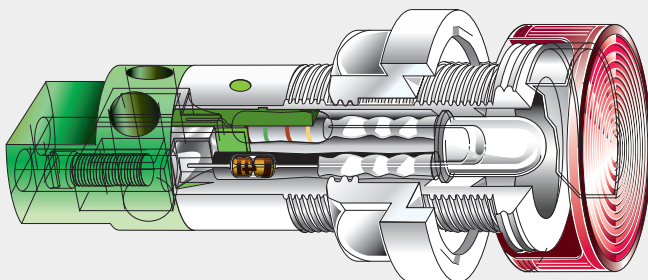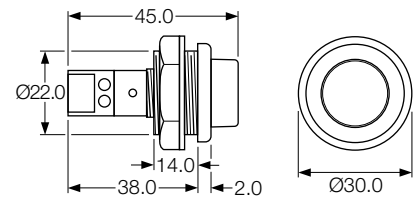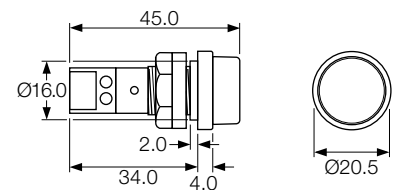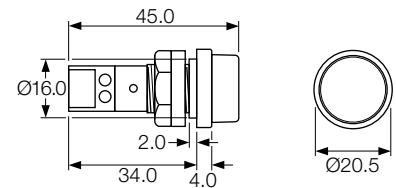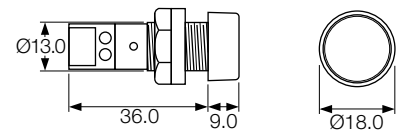

Select the version most suitable for your application from the 4 types shown.
Or call sales for availability to your special requirements.

Neon & LED Indicator Lights Sealed to IP52 and IP54

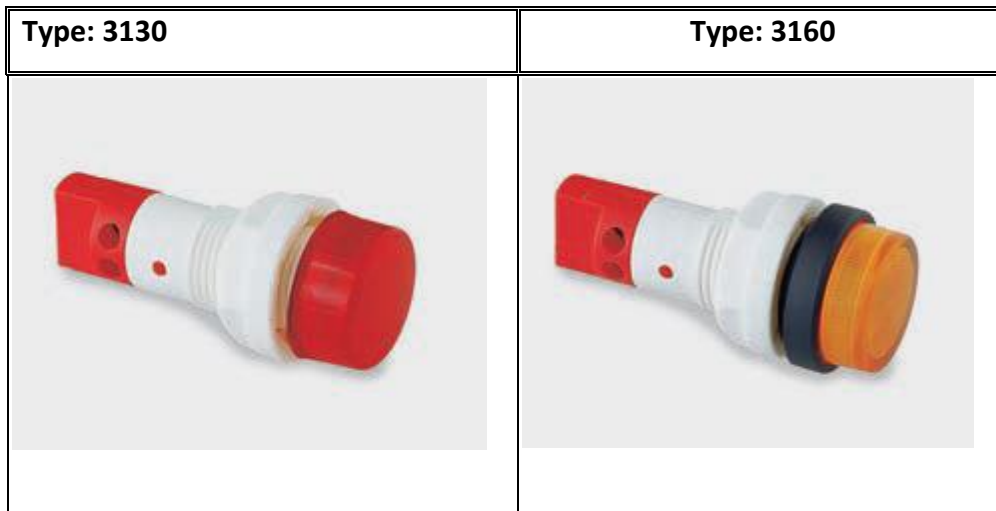

Part Number Ordering

Arcoelectric Part Number	Type	Light Source	Colour	Voltage
0731301230	3130	Neon	Red	230 V
0731303230	3130	Neon	Green	230 V
0731304230	3130	Neon	Amber	230 V
0731601230	3160	Neon	Red	230 V
0731603230	3160	Neon	Green	230 V
0731604230	3160	Neon	Amber	230 V
073130L128	3130	LED	Red	28 V
073130L228	3130	LED	Green	28 V
073130L428	3130	LED	Amber	28 V