


 


# Indicator Lights Neon, LED and Filament Lamp


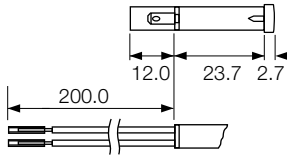

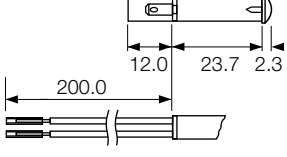

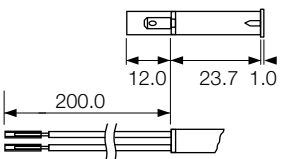



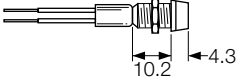

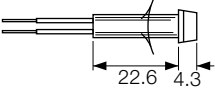
## Colours and voltages:


 

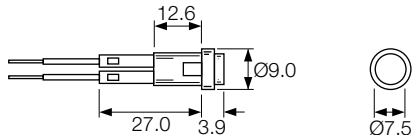

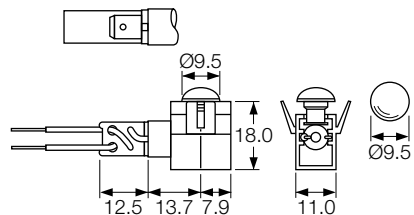

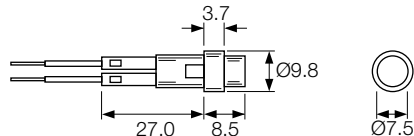

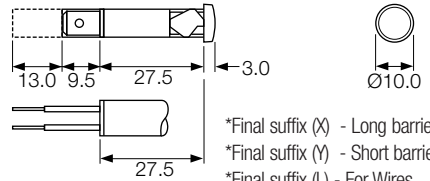

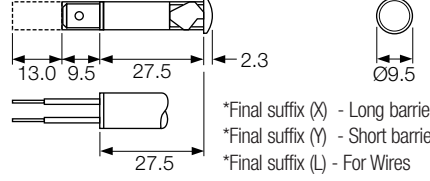
-  **Neon** Available with Red, Amber, Green or Clear lenses  
100/130V (marked 110V), 200/250V (marked 230V)
-  **LED - DC** Red, Yellow, Green, Blue, White  
2.0/2.2V Resistors for other voltages available.
-  **LED - AC** Red, Yellow, Green, Blue, White  
110-230V ac operation.
-  **Filament lamp** Available with Red, Amber, Green, Clear or Blue lenses  
6V, 12/14V, 24/28V.

- ▶ Neon, LED, mains LED or filament lamp
- ▶ Bezel sizes from 6.7 to 16.3mm diameter
- ▶ Red, amber, green, blue and clear lenses
- ▶ Red, yellow, green, blue and white LEDs
- ▶ Wide choice of styles

## To create a catalogue number:

Refer to the 2 columns below (terminal and type), then state: Lens colour, voltage and whether neon, LED or filament lamp

TERM	TYPE	PANEL & °C	ILLUM'N OPTIONS	APPROVAL	DIMENSIONS (mm)
B 2.8 L	(B) <b>0566 A</b> 	6.0 2.0max page 6	Neon LED-DC LED-AC	KEMA KEMA KEMA	 Ø7.0
B 2.8 L	(B) <b>0566 B</b> 	6.0 2.0max page 6	Neon LED-DC LED-AC	KEMA KEMA KEMA	 Ø7.0
B 2.8 L	(B) <b>0566 C</b> 	6.0 2.0max page 6	Neon LED-DC LED-AC	KEMA KEMA KEMA	 Ø7.0
C 6.3	(C) <b>0145 AA</b> 	5.8 3.0max page 6	Neon LED-DC LED-AC Filament lamp	FU KEMA KEMA KEMA	 Ø6.7
L W	(L) <b>1041 00</b> Chrome bezel 	6.3 6.3max page 6	Neon LED-DC LED-AC Filament lamp	FU KEMA KEMA KEMA	 Ø7.6
L W	(L) <b>1045 00</b> Chrome bezel available 	6.3 10.0max page 6	Neon LED-DC LED-AC Filament lamp	FU KEMA KEMA KEMA	 Ø7.6

TERM	TYPE	PANEL & °C	ILLUM'N OPTIONS	APPROVAL	DIMENSIONS (mm)
L W	(L) <b>0245 00</b> Chrome bezel available 	7.1 6.3max page 6	DC AC	RU KEMA KEMA KEMA	
L	L <b>2950 00</b> Chrome bezel available 	8.0 0.8-1.6 page 6	DC AC	RU KEMA KEMA	
L C 6.3	(L) <b>0195 BB</b> 	8.0 0.8-3.0 page 6		RU KEMA KEMA	
L	L <b>2951 00</b> Chrome bezel 	8.0 0.8-1.6 page 6	DC AC	RU KEMA KEMA KEMA	
L H 4.8	(H) <b>0568 A(*)</b> Deep lens profile  (VDE at T100)	8.0 0.8-3.5 page 6	DC	RU KEMA KEMA	 *Final suffix (X) - Long barrier *Final suffix (Y) - Short barrier *Final suffix (L) - For Wires
L H 4.8	(H) <b>0568 B(*)</b> Shallow lens profile 	8.0 0.8-3.5 page 6	DC	RU KEMA KEMA	 *Final suffix (X) - Long barrier *Final suffix (Y) - Short barrier *Final suffix (L) - For Wires

Indicators

# Indicator Lights Neon, LED and Filament Lamp

Type: L 2950 00



## Part Number Ordering

Arcoelectric Part Number	Type	Light Source	Colour	Voltage
L295000NAA	L 2950 00	Neon	Red	230 V
L295000NAC	L 2950 00	Neon	Amber	230 V
L295000NAD	L 2950 00	Neon	Clear	230 V
L295000NAE	L 2950 00	Neon	Green	230 V