

A	V	Hz	2P+E	EARTH REL. POS.	3P+E	EARTH REL. POS.	3P+N+E	EARTH REL. POS.
CURRENT	VOLTAGE	FREQUENCY						

## Plugs

**CEE NORM**

16	110	50 - 60	210100	4				
	240	50 - 60	210094	6				
	415	50 - 60			210095	6	212001	6
32	110	50 - 60	210330	4				
	240	50 - 60	210096	6				
	415	50 - 60			210097	6	212002	6



**QUICK CONNECT®**  
**Plug with Cable Sleeve**

- Screwless terminals
- IP14 Splashproof

16	110	50 - 60	2125	4	21872	4	210176	4
	240	50 - 60	2126	6	2129	9	21840	9
	415	50 - 60	21843	9	2130	6	2136	6
32	110	50 - 60	2137	4	21873	4	210193	4
	240	50 - 60	2138	6	2141	9	21842	9
	415	50 - 60	21844	9	2142	6	2148	6



**QUICK CONNECT®**  
**Plug with Multi-Grip Cable Gland**

- Screwless terminals
- IP14 Splashproof

63	110	50 - 60						
	240	50 - 60						
	415	50 - 60			210761	6	210765	6

63A with screwless terminals and pilot contact

**Note:** This pilot contact should **NOT** be counted as a main 'pin'



**QUICK CONNECT®**  
**Plug with Multi-Grip Cable Gland**

- Screwless terminals
- Splashproof
- IP14


**QUICK CONNECT®**



Other voltages and frequencies are available on request. Contact CEE Norm UK for further details

# Dimensions

**CEE** NORM

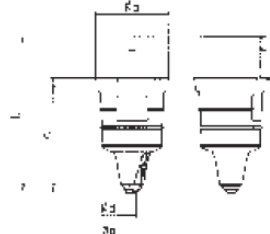


	16			32		
	3	4	5	3	4	5
Amperes						
Poles						
Ø a	53	59	66	70	70	75
b	125.5	133	141	165	165	165
c	86.5	96.5	104.5	119	119	119
Ø d	5	5	7	8	8	8.5
Ø e	14.5	15.5	17.5	23.5	23.5	26
Conductor mm <sup>2</sup> min	1	1	1	2.5	2.5	2.5
Conductor mm <sup>2</sup> max	2.5	2.5	2.5	6	6	6

## QUICK CONNECT<sup>®</sup> Plug

- Moulded cable sleeve
- 4-point (quarter turn) locking system
- Screwless terminals

 Splashproof

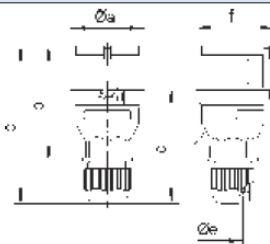


	16			32		
	3	4	5	3	4	5
Amperes						
Poles						
Ø a	53	60	66	74.5	74.5	74.5
b	93.5	100.5	103	121	121	121.5
c	134	141	142	174	174	174.5
d	97.5	104.5	105.5	128	128	128.5
Ø e	18	18	18	23	23	23
f	57.5	64.5	70.5	78	78	80
Conductor mm <sup>2</sup> min	1	1	1	2.5	2.5	2.5
Conductor mm <sup>2</sup> max	2.5	2.5	2.5	6	6	6

## QUICK CONNECT<sup>®</sup> Plug with Multi-Grip Cable Gland

- Screwless terminals
- 4-point (quarter turn) locking system
- Multi-Grip cable gland system with moulded-in gasket

 Splashproof

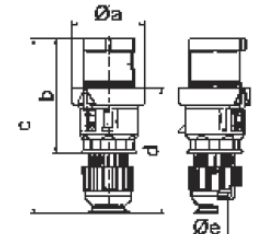

	63	
	4	5
Amperes		
Poles		
Ø a	96	96
b	153	153
c	233	233
d	167	167
Ø e	36	36
Conductor mm <sup>2</sup> min	6	6
Conductor mm <sup>2</sup> max	16	16

## QUICK CONNECT<sup>®</sup> Plug with Multi-Grip Cable Gland

- Multi-Grip cable gland system with moulded-in gasket
- Max cable diameter 36mm
- Screwless terminals

 Splashproof

**QUICK  CONNECT<sup>®</sup>**