

PANEL MOUNT INDICATOR, NON-RELAMPABLE

LED TECHNOLOGY, SUNLIGHT VISIBILITY


MOUNTING HOLE, Ø 0.690"

PART NO.	LENS COLOR	VOLTAGE (DC)	CURRENT [mA]	RATED LIFE HOURS
LED 6V SERIES				
WL-557-1502-303Q	RED	5V-7V	20mA	60,000
WL-557-1702-303Q	YELLOW	5V-7V	20mA	60,000
WL-557-1602-303Q	GREEN	5V-7V	20mA	60,000
WL-557-1802-303Q	BLUE	5V-7V	20mA	60,000
WL-557-1002-303Q	WHITE	5V-7V	20mA	60,000
LED 12V SERIES				
WL-557-1503-303Q	RED	12V-14V	20mA	60,000
WL-557-1703-303Q	YELLOW	12V-14V	20mA	60,000
WL-557-1603-303Q	GREEN	12V-14V	20mA	60,000
WL-557-1803-303Q	BLUE	12V-14V	20mA	60,000
WL-557-1003-303Q	WHITE	12V-14V	20mA	60,000
LED 24V SERIES				
WL-557-1505-303Q	RED	24V-28V	20mA	60,000
WL-557-1705-303Q	YELLOW	24V-28V	20mA	60,000
WL-557-1605-303Q	GREEN	24V-28V	20mA	60,000
WL-557-1805-303Q	BLUE	24V-28V	20mA	60,000
WL-557-1005-303Q	WHITE	24V-28V	20mA	60,000

NOTES

1. Recommended panel thickness
0.050" to 0.187"
2. .250 x .032 terminals are standard
3. Storage temperature
 T_{STG} : -25°C - +80°C
4. Ambient temperature
 T_A : -20°C - +60°C
5. Voltage tolerance
 V_{OP} : $\pm 10\%$
6. DC operation only
7. Sunlight Visible, 3000 mcd minimum
8. Body material
Nylon, black
9. Lens material
Polycarbonate
10. Terminals
Quick-connect, tinned brass
11. Gasket
Buna-N
12. Mounting hardware (nut, lock washer, and gasket) included

DIMENSIONAL CHARACTERISTICS

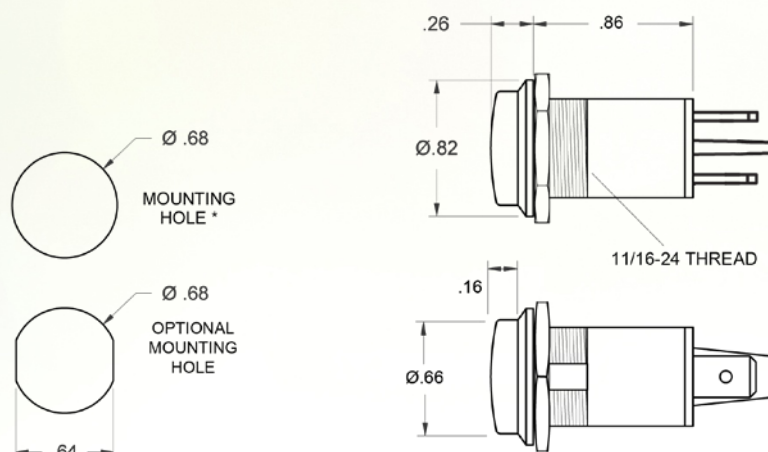

unless otherwise specified, all dimensions are in inches

OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.

CERTIFICATIONS

UL (E340667), RoHS



- Splash proof
- Outdoor applications
- NEMA 3-R



PANEL MOUNT INDICATOR, NON-RELAMPABLE

LED TECHNOLOGY, SUNLIGHT VISIBILITY


MOUNTING HOLE, Ø 0.690"

PART NO.	LENS COLOR	VOLTAGE (AC)	CURRENT [mA]	RATED LIFE HOURS
LED 125VAC SERIES				
WL-557-1507-303Q	RED	105-125VAC	20mA	60,000
WL-557-1707-303Q	YELLOW	105-125VAC	20mA	60,000
WL-557-1607-303Q	GREEN	105-125VAC	20mA	60,000
WL-557-1807-303Q	BLUE	105-125VAC	20mA	60,000
WL-557-1007-303Q	WHITE	105-125VAC	20mA	60,000

NOTES

1. Recommended panel thickness
0.050" to 0.187"
2. .250 x .032 terminals are standard
3. Storage temperature
 T_{STG} : -25°C - +80°C
4. Ambient temperature
 T_A : -20°C - +60°C
5. Voltage tolerance
 V_{OP} : ±10%
6. AC operation only
7. Sunlight Visible, 3000 mcd minimum
8. Body material
Nylon, black
9. Lens material
Polycarbonate
10. Terminals
Quick-connect, tinned brass
11. Gasket
Buna-N
12. Mounting hardware (nut, lock washer, and gasket) included

DIMENSIONAL CHARACTERISTICS

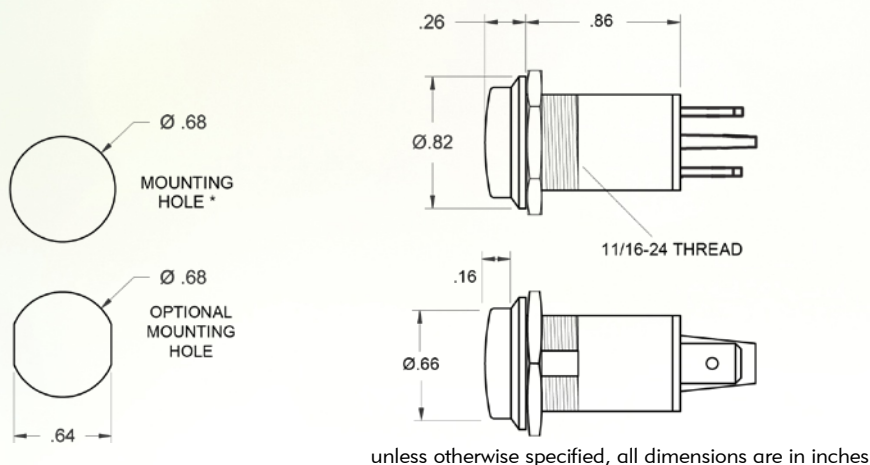

CERTIFICATIONS

UL (E340667), RoHS



- Splash proof
- Outdoor applications
- NEMA 3-R



OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.

