

PANEL MOUNT INDICATOR, NON-RELAMPABLE

LED TECHNOLOGY

MOUNTING HOLE, Ø 0.380"

PART NO.	LENS COLOR	VOLTAGE	CURRENT [mA]	RATED LIFE HOURS
LED 12V SERIES				
WL-6091QM1-12V	RED	12V-14V	20mA	100,000
WL-6091QM3-12V	AMBER	12V-14V	20mA	100,000
WL-6091QM5-12V	GREEN	12V-14V	20mA	100,000
WL-6091QM6-12V	BLUE	12V-14V	20mA	100,000
WL-6091QM7-12V	YELLOW	12V-14V	20mA	100,000
LED 24V SERIES				
WL-6091QM1-24V	RED	24V-28V	20mA	100,000
WL-6091QM3-24V	AMBER	24V-28V	20mA	100,000
WL-6091QM5-24V	GREEN	24V-28V	20mA	100,000
WL-6091QM6-24V	BLUE	24V-28V	20mA	100,000
WL-6091QM7-24V	YELLOW	24V-28V	20mA	100,000

NOTES


1. Recommended panel thickness
0.030" to 0.250"
2. .187 x .020 terminals are standard
3. Storage temperature
 T_{STG} : -25°C - +80°C
4. Ambient temperature
 T_A : -20°C - +60°C
5. Voltage tolerance
 V_{OP} : ±10%
6. Body material
Nylon, white
7. Lens material
Polycarbonate
8. Bezel material
Stainless steel
9. Terminals
Quick-connect, tinned brass
10. Gaskets
Buna-N
11. Mounting hardware (nut, lock washer, and gasket) included

CERTIFICATIONS

UL (E340667), RoHS



DIMENSIONAL CHARACTERISTICS

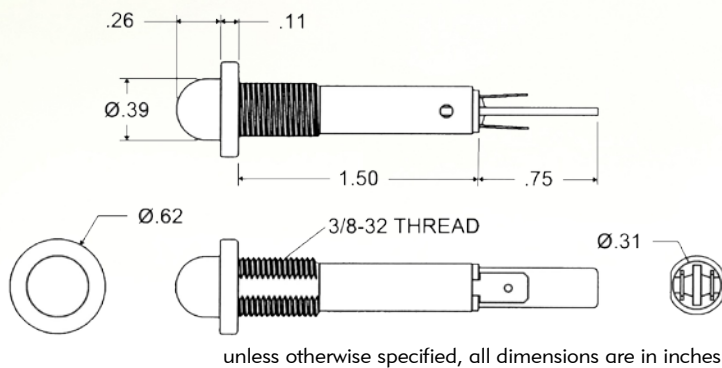

OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.

- Splash proof
- Outdoor applications
- NEMA 3-R

