

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19160-0039](#)
Status: **Active**
Overview: [Splices](#)
Description: Twist Lock Splice for 14-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)

Agency Certification

CSA LR700095
UL E32244

General

Product Family Splices
Series [19160](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
MolexKits Yes
Overview [Splices](#)
Product Name Closed-End Twist Lock
UPC 800753110434

Physical

Barrel Type Closed
Color - Resin GREY
Flammability 94V-2
Insulation Nylon (PA)
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.469/g
Packaging Type Bag
Temperature Range - Operating 105°C
Wire Insulation Diameter 6.60mm max.
Wire Size AWG 14, 16, 18, 20, 22
Wire Size mm² 2.00 - 3.50

Electrical


Voltage - Maximum 300V

Material Info

Old Part Number TL-G

Reference - Drawing Numbers

Product Specification PS-19902-013
Sales Drawing SD-19160-005

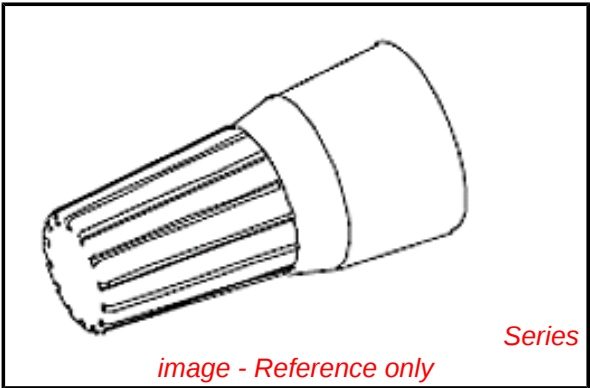

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19160Series](#)